



Kabel koneksi

VSTGH030MSS0020A03DOGF030MSS

Produk tidak tersedia - entri arsip



Data kelistrikan

|                        |     |            |
|------------------------|-----|------------|
| Tegangan pengoperasian | [V] | 10...30 DC |
| Kelas perlindungan     |     | III        |

Kondisi pengoperasian

|              |      |          |
|--------------|------|----------|
| Suhu sekitar | [°C] | -25...90 |
| Perlindungan |      | IP 67    |

Data teknis


|                       |                          |
|-----------------------|--------------------------|
| Material              | TPU                      |
| Material bodi detakan | TPU                      |
| Material mur          | kuningan, berlapis nikel |

Keterangan

|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

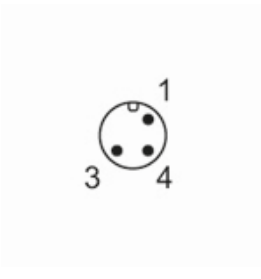



## Kabel koneksi

VSTGH030MSS0020A03DOGF030MSS

### Koneksi listrik

Kabel: 20 m, PUR / PVC; 3 x 0.34 mm<sup>2</sup>

### Koneksi



### Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

