




Kabel koneksi

VDOAF030MSS00,6A03STGH030MSS

Produk tidak tersedia - entri arsip

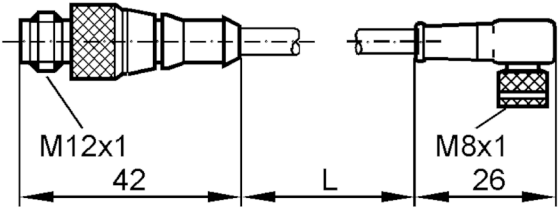

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		III
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel






Kabel koneksi

VDOAF030MSS00,6A03STGH030MSS

Koneksi listrik

Kabel: 0.6 m, PUR / PVC; 3 x 0.34 mm²

Koneksi

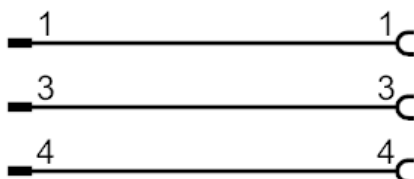

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

