



Kabel koneksi


VDOGH040MSS0010A04STGH040MSS

Produk tidak tersedia - entri arsip



Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 42
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

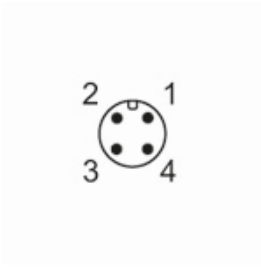



Kabel koneksi

VDOGH040MSS0010A04STGH040MSS

Koneksi listrik

Kabel: 10 m, PUR / PVC; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

