




Kabel koneksi

VDOAH040MSS0002A04STAH040MSS

Produk tidak tersedia - entri arsip

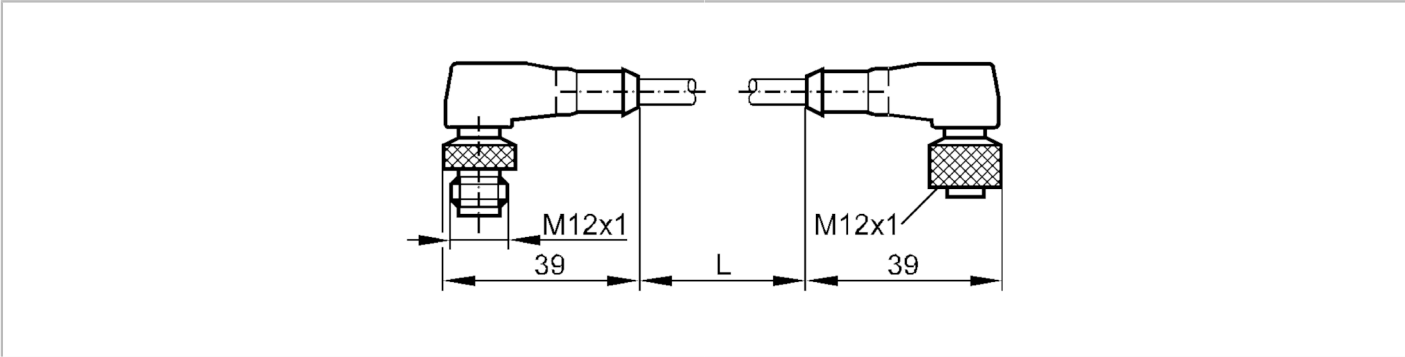

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis


Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

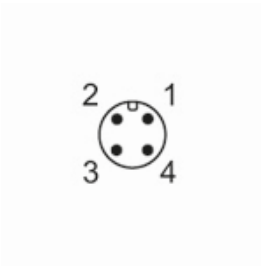



Kabel koneksi

VDOAH040MSS0002A04STAH040MSS

Koneksi listrik

Kabel: 2 m, PUR / PVC, oranye, Ø 5 mm; 4 x 0.25 mm²

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

