


Kabel koneksi Y

YDOAH032MSS0001H03STGH040MSS

Produk tidak tersedia - entri arsip

Produk alternatif: EVC437

Ketika memilih produk dan aksesoris alternatif, perhatikan bahwa data teknis mungkin berbeda!

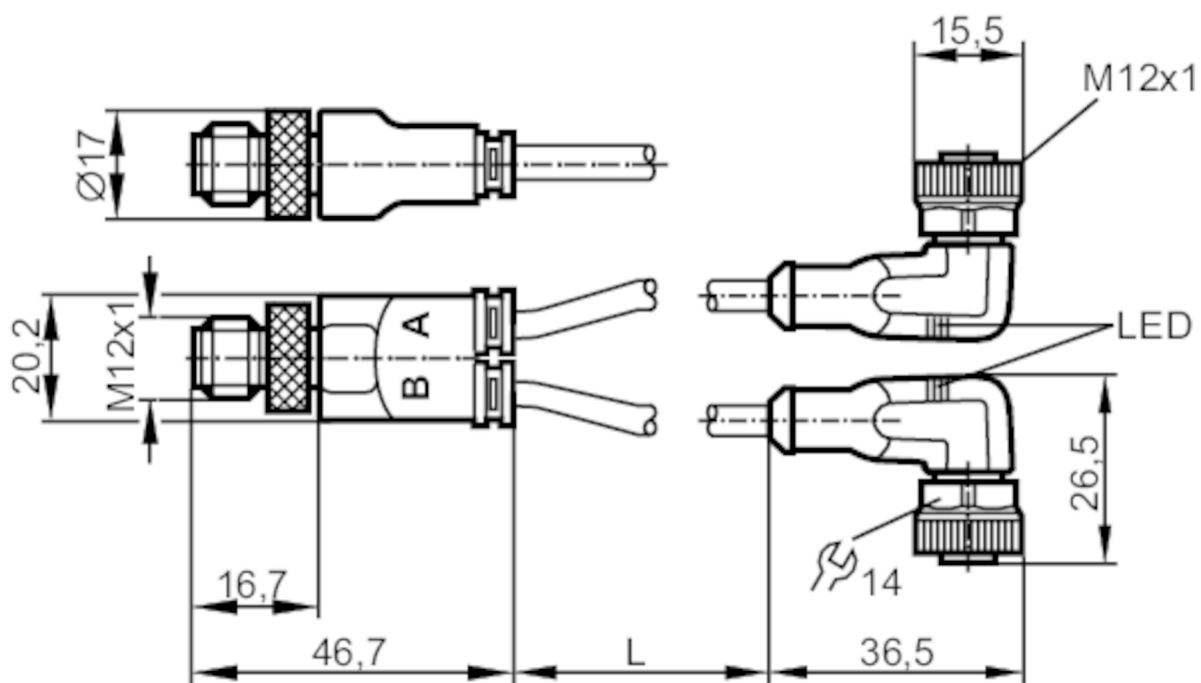

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	0.108
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Material penyegel		FKM
Jumlah port kotak splitter		2

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi Y

YDOAH032MSS0001H03STGH040MSS

Koneksi listrik


Kabel: 1 m, PUR, hitam, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - colokan C

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU, hitam; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm



Koneksi

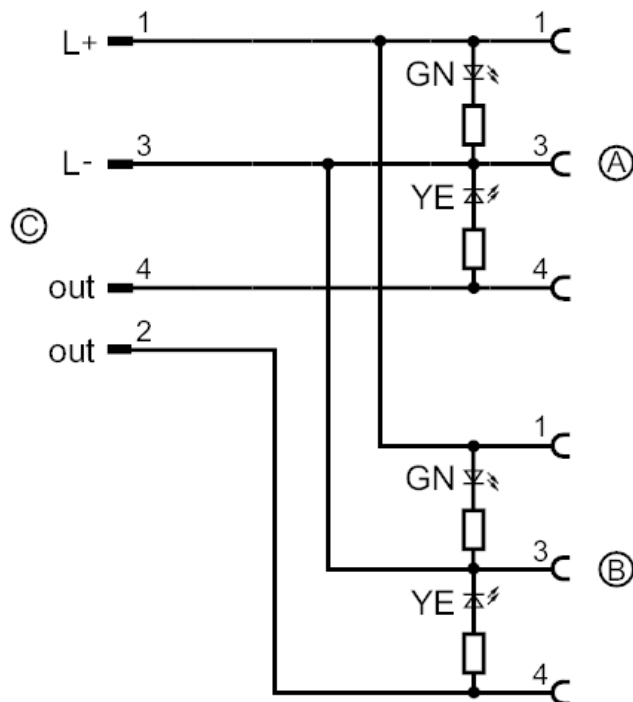

Koneksi listrik - soket A

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, hitam transparan; Penguncian: kuningan, berlapis nikel; Segel: FKM; Torsi pengencangan: 0.6...1.5 Nm



E70063



Kabel koneksi Y

YDOAH032MSS0001H03STGH040MSS

Koneksi listrik - soket B

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, hitam transparan; Penguncian: kuningan, berlapis nikel; Segel: FKM; Torsi pengencangan: 0.6...1.5 Nm

