


E70065



Kabel koneksi Y

YDOAH032MSS0002H03STGH040MSS

Produk tidak tersedia - entri arsip

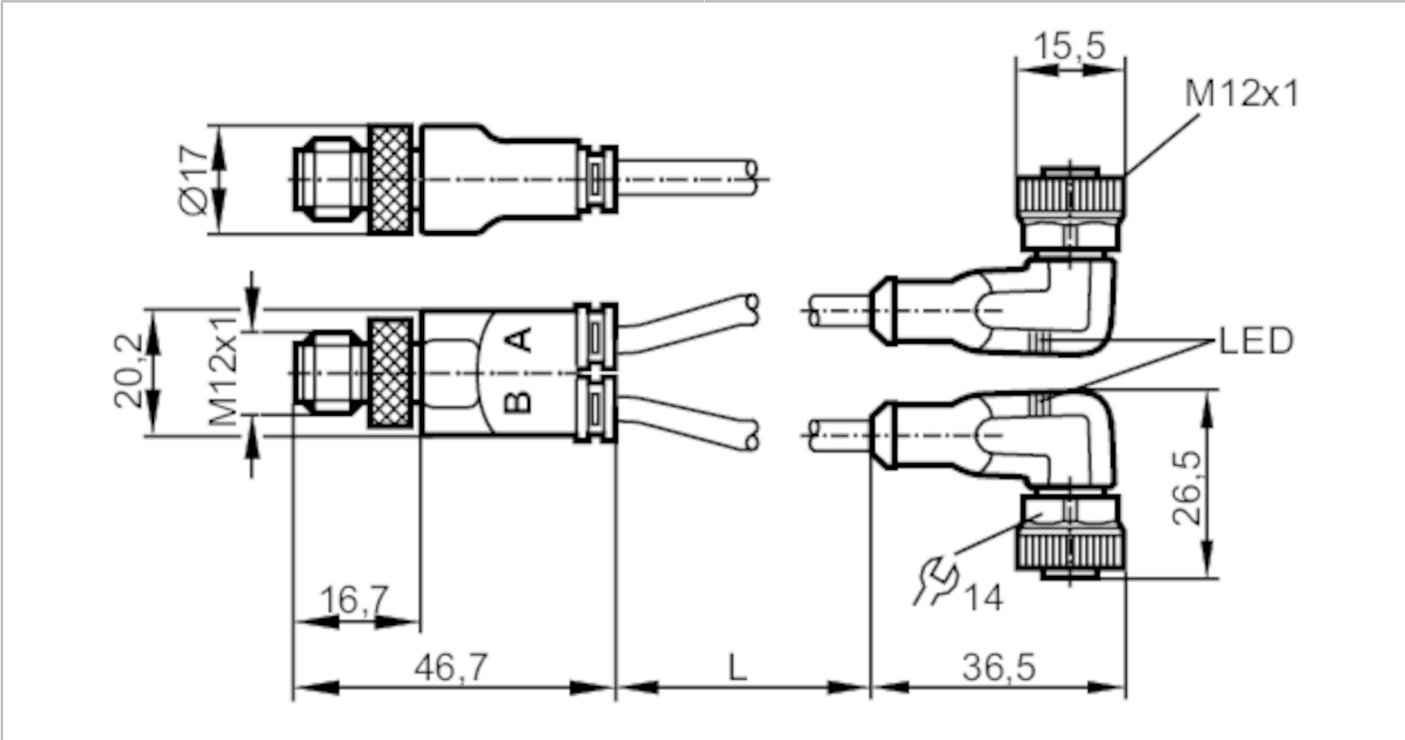

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Berat	[g]	0.163
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Material penyegel		FKM
Jumlah port kotak splitter		2
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket		1 buah

Kabel koneksi Y

YDOAH032MSS0002H03STGH040MSS

Koneksi listrik


Kabel: 2 m, PUR, hitam, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - colokan C

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU, hitam; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm



Koneksi

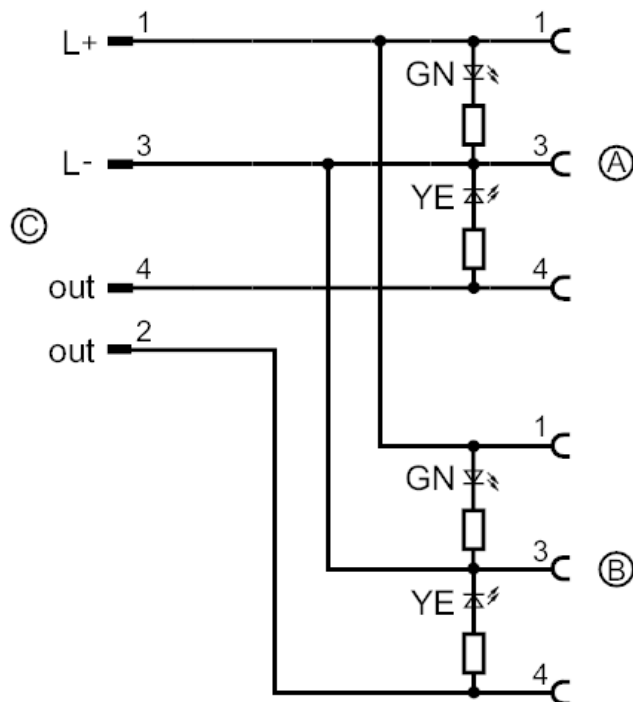

Koneksi listrik - soket A

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, hitam transparan; Penguncian: kuningan, berlapis nikel; Segel: FKM; Torsi pengencangan: 0.6...1.5 Nm





Kabel koneksi Y

YDOAH032MSS0002H03STGH040MSS

Koneksi listrik - soket B

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, hitam transparan; Penguncian: kuningan, berlapis nikel; Segel: FKM; Torsi pengencangan: 0.6...1.5 Nm

