


E70124



Kabel koneksi

VDOGH040PL-0002A03STGH040MSS

Produk tidak tersedia - entri arsip

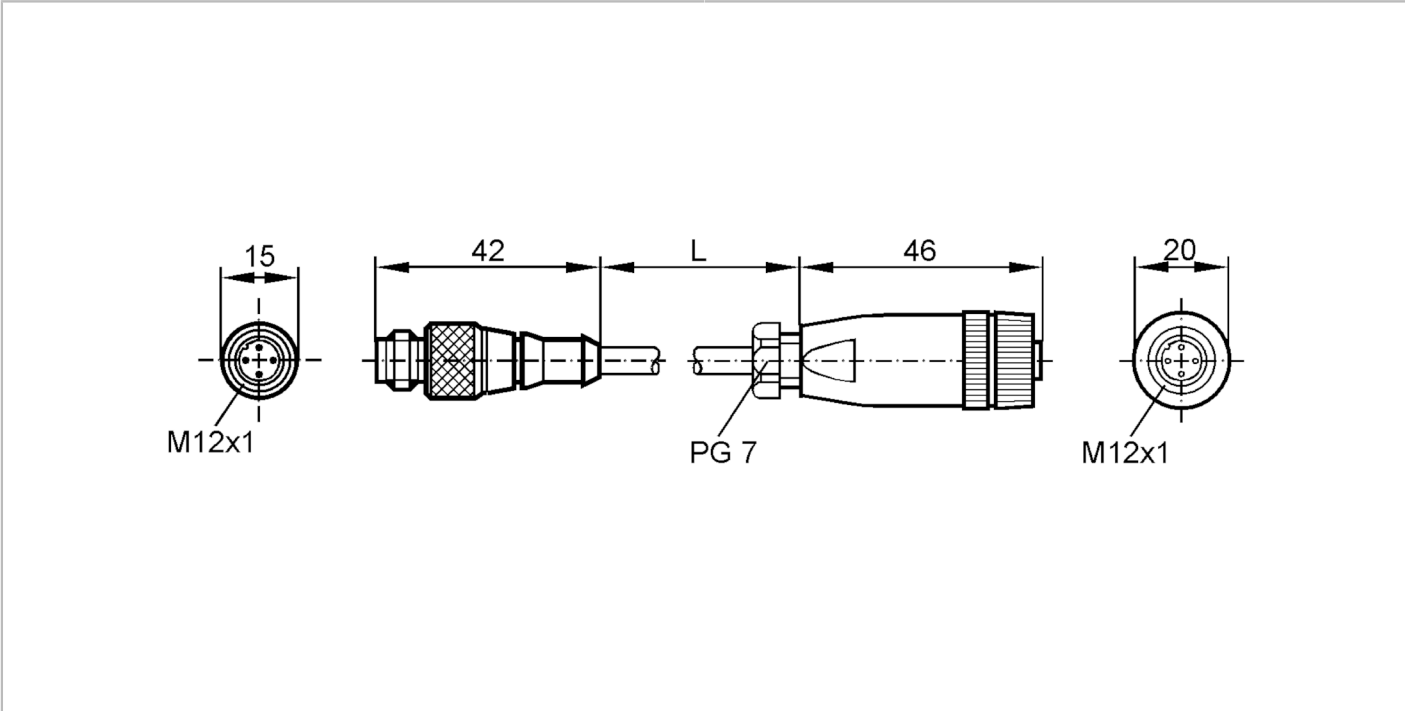

Data kelistrikan		
Tegangan pengoperasian	[V]	10...36 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 42
Material		TPU; PBT
Material bodi detakan		TPU / PBT
Material mur		PBT / PA
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		
Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU / PBT; Penguncian: PBT		






Kabel koneksi

VDOGH040PL-0002A03STGH040MSS

Koneksi listrik

Kabel: 2 m, PUR / PVC; 4 x 0.25 mm²

Koneksi

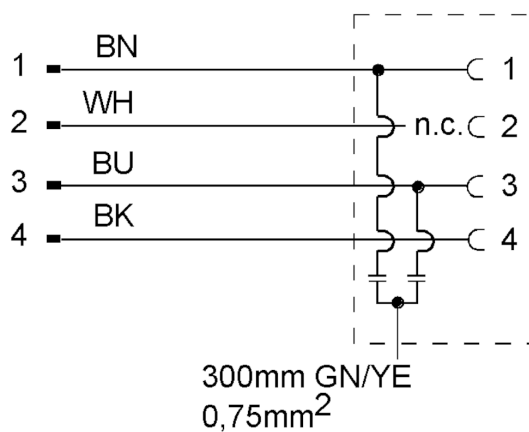

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU / PBT; Penguncian: PA

