


E70125



Kabel koneksi

VDOGH040PL-0005A03STGH040MSS

Produk tidak tersedia - entri arsip

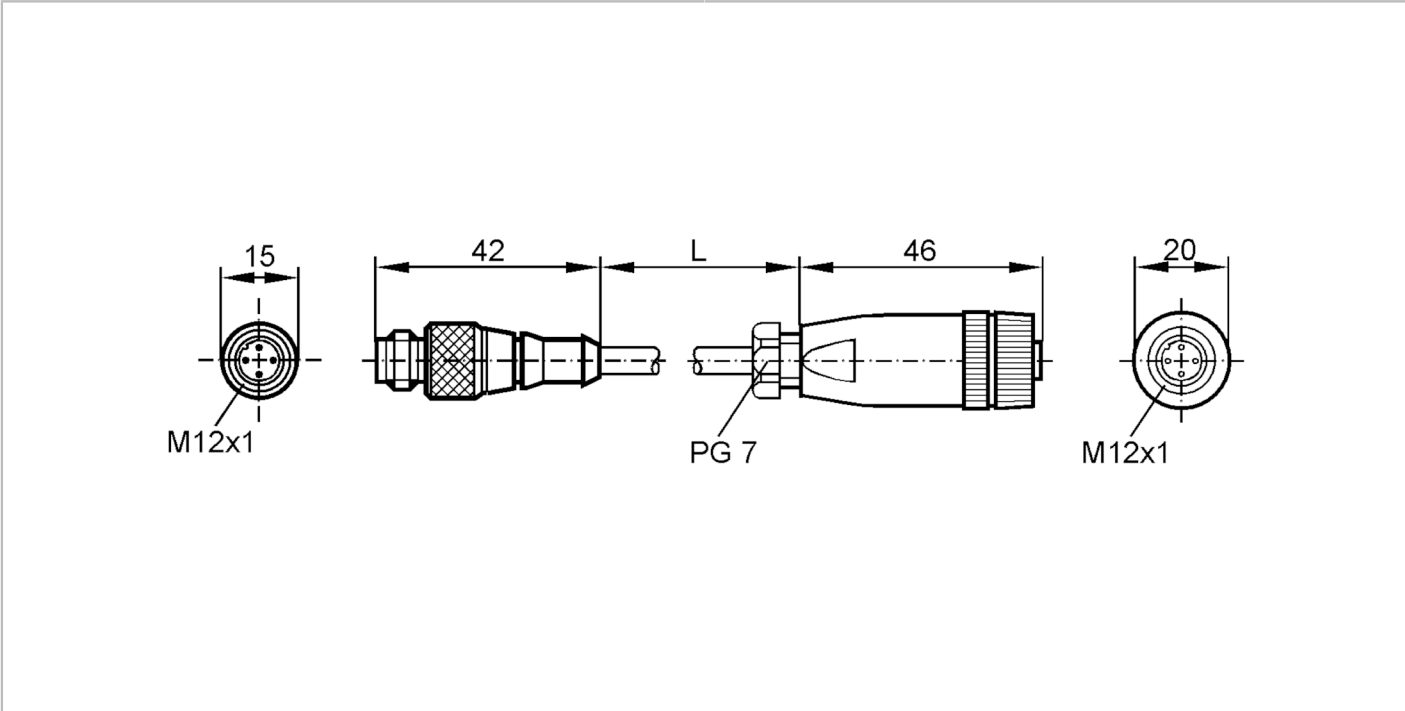

| Data kelistrikan          |      |              |
|---------------------------|------|--------------|
| Tegangan pengoperasian    | [V]  | 10...36 DC   |
| Kondisi pengoperasian     |      |              |
| Suhu sekitar              | [°C] | -25...90     |
| Perlindungan              |      | IP 67        |
| Data teknis               |      |              |
| Dimensi                   | [mm] | 15 x 15 x 42 |
| Material                  |      | TPU; PBT     |
| Material bodi detakan     |      | TPU / PBT    |
| Material mur              |      | PBT / PA     |
| Keterangan                |      |              |
| Jumlah paket              |      | 1 buah       |
| Koneksi listrik - colokan |      |              |

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU / PBT; Penguncian: PBT



# E70125




## Kabel koneksi

VDOGH040PL-0005A03STGH040MSS

### Koneksi listrik

Kabel: 5 m, PUR / PVC; 4 x 0.25 mm<sup>2</sup>

### Koneksi

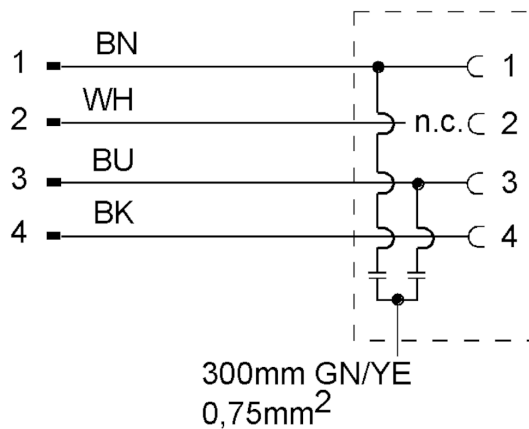

### Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU / PBT; Penguncian: PA

