


E70129



Kabel jumper dengan soket katup

VDAA0401--S0002A03STAH030MSS

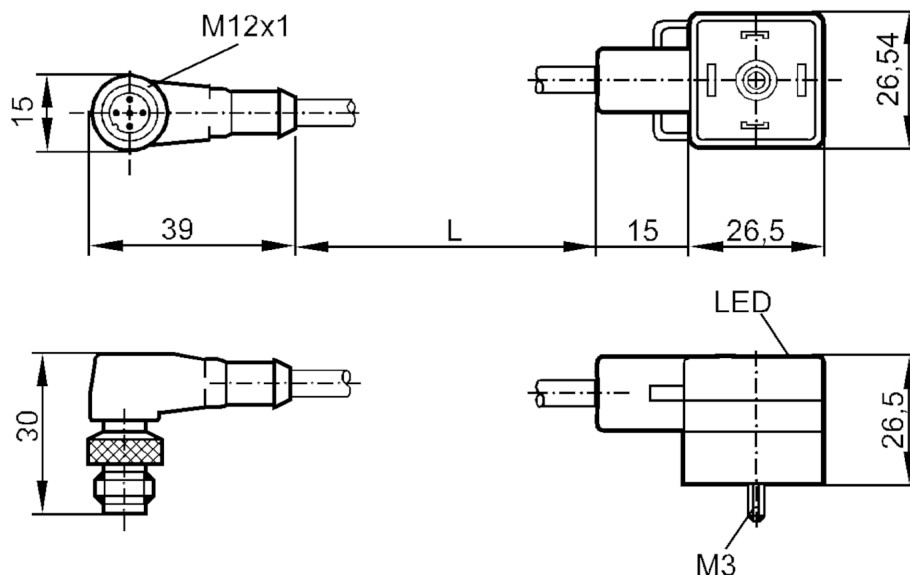


Aplikasi	
Fitur khusus	Bebas halogen
Data kelistrikan	
Tegangan pengoperasian [V]	< 24 AC/DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...90
Perlindungan	IP 67
Data teknis	
Berat [g]	138.5
Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel
Aksesori	
Item dikirim	sekrup panel untuk pelabelan
Keterangan	
Jumlah paket	1 buah

Kabel jumper dengan soket katup

VDAA0401--S0002A03STAH030MSS

Koneksi listrik - soket

 
Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel



Koneksi listrik

Kabel: 2 m, PUR, Bebas halogen, hitam, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Koneksi

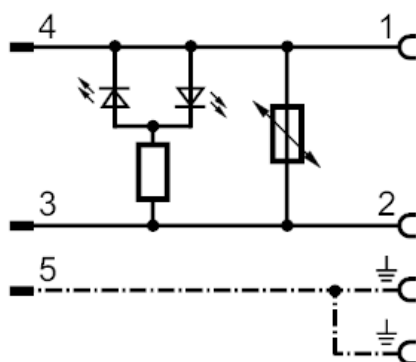

Koneksi listrik - soket

Konektor: 1 x katup tipe A DIN, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

