


E70142



Soket berkabel

SDOGL070PLSFKPG

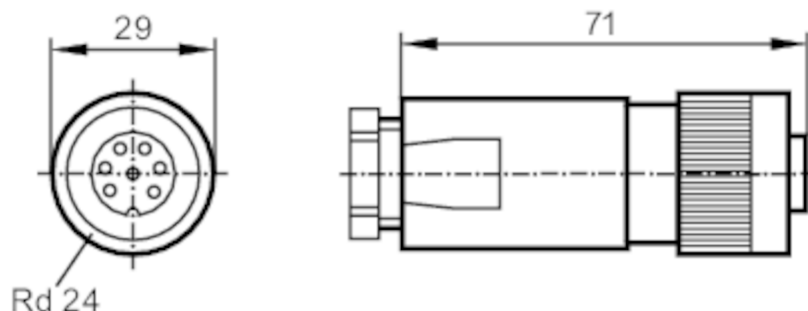

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 45 AC / < 70 DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-40...100

Perlindungan

IP 67

Data teknis

Berat

[g]

49.4

Dimensi

[mm]

29 x 29 x 71

Material

PBT

Material bodi detakan

PBT

Material mur

PBT

Keterangan

Jumlah paket

1 buah

E70142



Soket berkabel

 
SDOGL070PLSFKPG

Koneksi listrik

terminal: ...2.5 mm²; Selubung kabel: Ø 10...12 mm

Koneksi listrik - soket

Konektor: 1 x Rd24, lurus; pengkodean: A; Bodi cetakan: PBT; Penguncian: PBT; Kontak: dilapisi emas



Koneksi

