


E70143



Kabel jumper dengan soket katup

VVDAB031--S00,3A03STAH030VAS

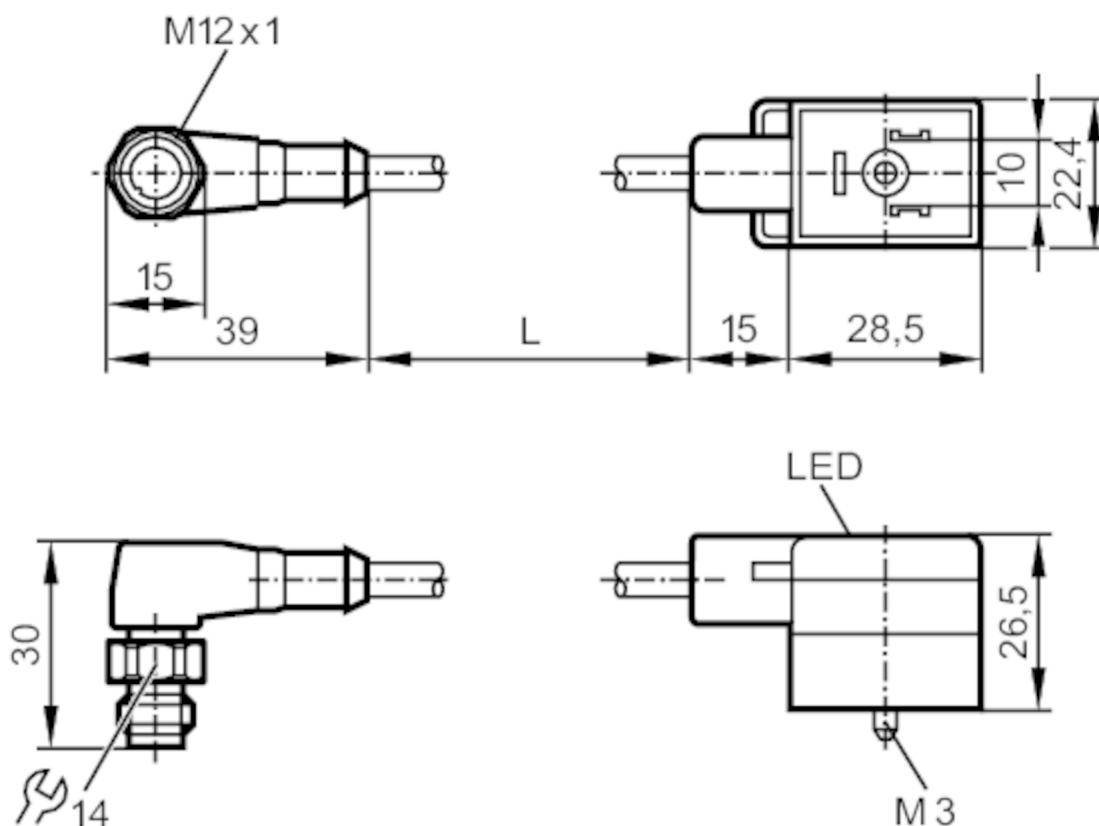

Aplikasi		
Fitur khusus	Bebas halogen	
Data kelistrikan		
Tegangan pengoperasian	[V]	< 24 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan	IP 67	
Data teknis		
Berat	[g]	58.7
Dimensi	[mm]	30 x 15 x 39
Material	PUR	
Material bodi detakan	PUR	
Material mur	baja tahan karat (1.4404 / 316L)	
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Aksesori		
Item dikirim	sekrup	
	panel untuk pelabelan	

**Kabel jumper dengan soket katup**

VVDAB031--S00,3A03STAH030VAS


Keterangan

Jumlah paket

1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: baja tahan karat (1.4404 / 316L)

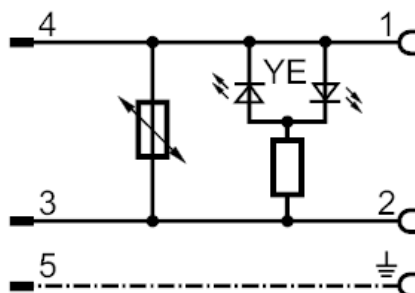**Koneksi listrik**Kabel: 0.3 m, PUR, Bebas halogen, hitam, Ø 5.5 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)**Koneksi****Koneksi listrik - soket**

Konektor: 1 x katup tipe B DIN, bersiku; Bodi cetakan: PUR; Penguncian: baja tahan karat (1.4404 / 316L)

