


E70170



Soket berkabel

SDOGB030ZDSFKPG

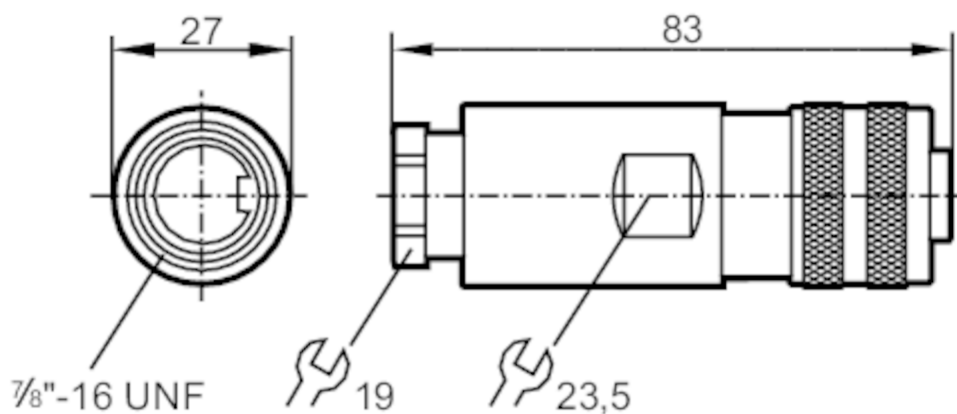

Data kelistrikan

Tegangan pengoperasian	[V]	< 300 AC/DC
Total beban arus maks.	[A]	12

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67

Data teknis

Berat	[g]	54.2
Dimensi	[mm]	27 x 27 x 83
Material bodi detakan		PBT
Material mur		seng tuang

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E70170



Soket berkabel

SDOGB030ZDSFKPG

Koneksi listrik

terminal: ...1.5 mm²; Selubung kabel: Ø 8...10 mm

Koneksi listrik - soket

Konektor: 1 x 7/8", lurus; Bodi cetakan: PBT; Penguncian: seng tuang



Koneksi

