


E70202



Kabel koneksi

VDOAH030VAS0001E03STGH030VAS

Produk tidak tersedia - entri arsip

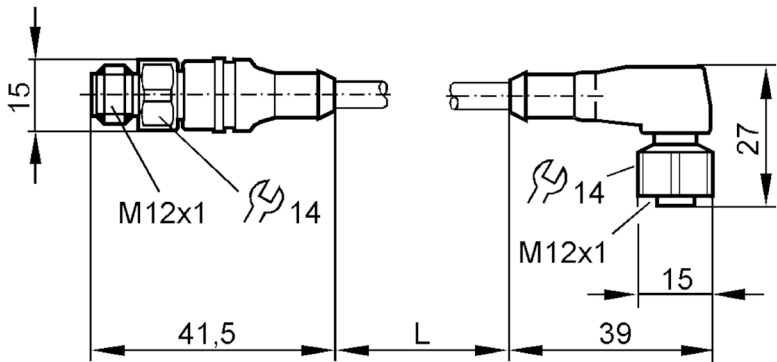

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...100
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 41.5
Material		PVC
Material bodi detakan		PVC
Material mur		baja tahan karat (1.4404 / 316L)
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4404 / 316L)






Kabel koneksi

VDOAH030VAS0001E03STGH030VAS

Koneksi listrik

Kabel: 1 m, PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi

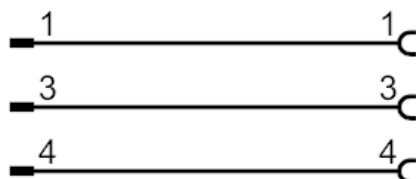

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4404 / 316L)

