


E70203



Jumper Y dengan soket katup

YVDAA042--S0001H03STGH050MSS

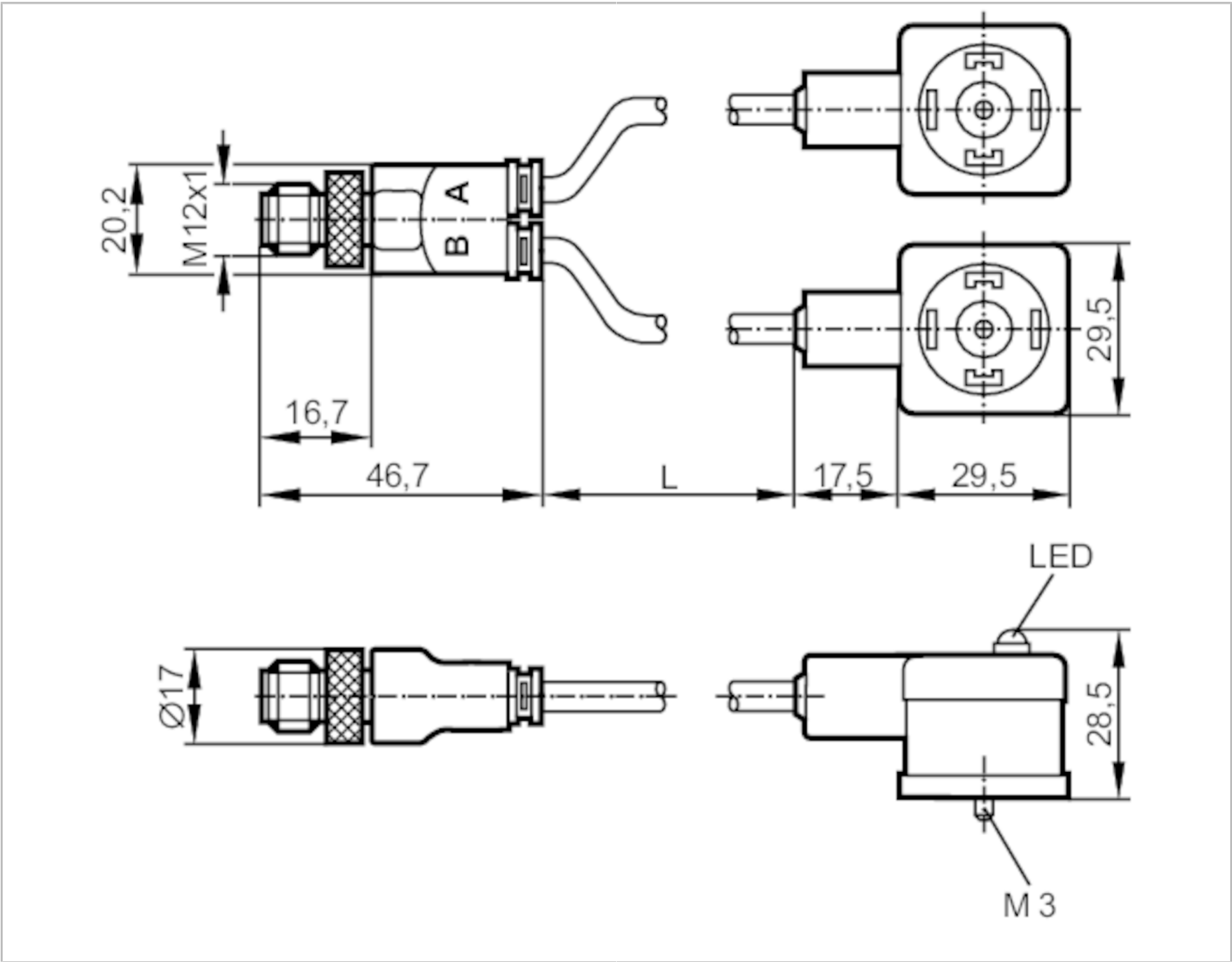


Aplikasi		
Fitur khusus	Bebas halogen	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Pelindung tegangan berlebih	ya; (VDR)	
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan	IP 65	
Data teknis		
Berat	[g]	183.5
Material	TPU	
Material bodi detakan	TPU	
Material mur	kuningan, berlapis nikel	
Elemen display/pengoperasian		
Display	status peralihan	2 x LED, kuning




Jumper Y dengan soket katup

YVDAA042--S0001H03STGH050MSS

Aksesori	
Item dikirim	sekrup panel untuk pelabelan
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - colokan	
Koneksi	

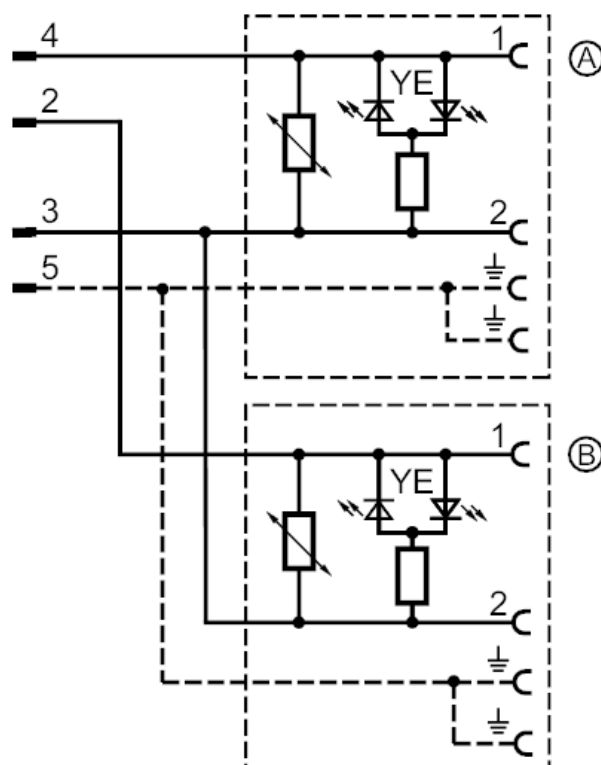

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

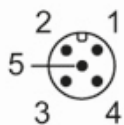

E70203



Jumper Y dengan soket katup

YVDAA042--S0001H03STGH050MSS

Koneksi listrik

Kabel: 1 m, PUR, Bebas halogen, hitam, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Koneksi listrik - soket

Konektor: 2 x katup tipe A DIN, bersiku; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

