


E70354



Konektor perpindahan isolasi kabel pipih AS-Interface

FCE Splitter ye/bk ProcessL

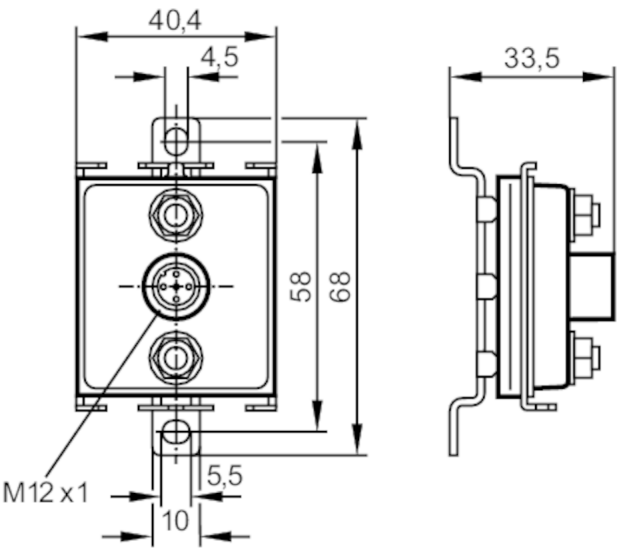

Aplikasi		
Desain	AS-i / 24 V	
Data kelistrikan		
Tegangan pengoperasian	[V]	26.5...31.6 DC; (AS-i)
Kelas perlindungan		III
Tegangan pengoperasian AUX DC	[V]	18...32
Total beban arus maks.	[A]	4; (AS-i: 2 A; AUX: 2 A)
Kondisi pengoperasian		
Suhu sekitar	[°C]	-30...80
Kelembapan udara relatif maks.	[%]	80; (31 °C; penurunan linear hingga 50% (40 °C))
Ketinggian maks. di atas permukaan laut	[m]	2000
Perlindungan		IP 67; IP 68; IP 69K
Tingkat kekotoran		2
Pengujian/persetujuan		
EME	EN 61000-6-2	
Data teknis		
Berat	[g]	112.3
Material	komponen logam: baja tahan karat (1.4404 / 316L); gasket karet untuk pin kontak: FPM; O-ring: EPDM	
Torsi pengencangan	[Nm]	2.5; (mur pengunci)
Aksesori		
Aksesori (opsional)	Kunci torsi, E70390	
Keterangan		
Jumlah paket	1 buah	




Konektor perpindahan isolasi kabel pipih AS-Interface

FCE Splitter ye/bk ProcessL

Koneksi listrik - soket

Konektor: 1 x M12; pengkodean: A; Torsi pengencangan: 1.2...1.4 Nm

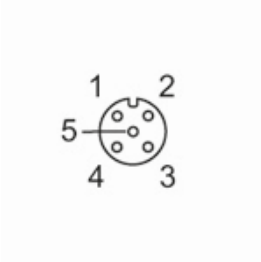

Koneksi	
1	AS-i +
2	0 V
3	AS-i -
4	+ 24 V
5	n. c.