


E70372



Konektor perpindahan isolasi kabel pipih AS-Interface

FCE Splitter ye/bk ProcessL

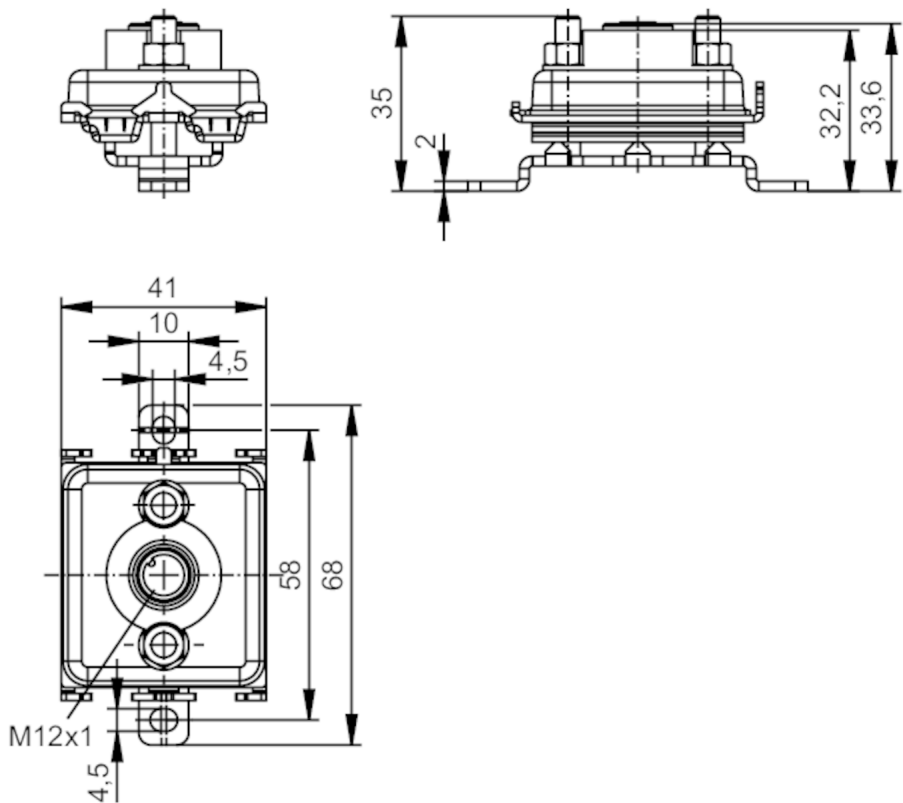

Aplikasi

Desain	AS-i / 24 V
--------	-------------

Data kelistrikan

Total beban arus maks.	[A]	2
------------------------	-----	---

Output

Desain kelistrikan	AS-i
--------------------	------

Kondisi pengoperasian

Suhu sekitar	[°C]	-30...80
Kelembapan udara relatif maks.	[%]	80; (31 °C; penurunan linear hingga 50% (40 °C))
Ketinggian maks. di atas permukaan laut	[m]	2000
Perlindungan		IP 67; IP 68; IP 69K
Tingkat kekotoran		2

Pengujian/persetujuan

EME	EN 61000-6-2
-----	--------------

 
Data teknis

Berat	[g]	104
Material		komponen logam: baja tahan karat (1.4404 / 316L); gasket karet untuk pin kontak: FPM; O-ring: EPDM
Torsi pengencangan	[Nm]	2.5; (mur pengunci)



Konektor perpindahan isolasi kabel pipih AS-Interface

FCE Splitter ye/bk ProcessL

Aksesori	
Aksesori (opsional)	Kunci torsi, E70390
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - soket	
Konektor: 1 x M12; pengkodean: A; Torsi pengencangan: 1.2...1.4 Nm	
	
Koneksi	
1	AS-i +
2	0 V
3	AS-i -
4	+ 24 V
5	n. c.