


E7354A



Konektor perpindahan isolasi kabel pipih AS-Interface

FCE Splitter ye/bk II 3D/3G

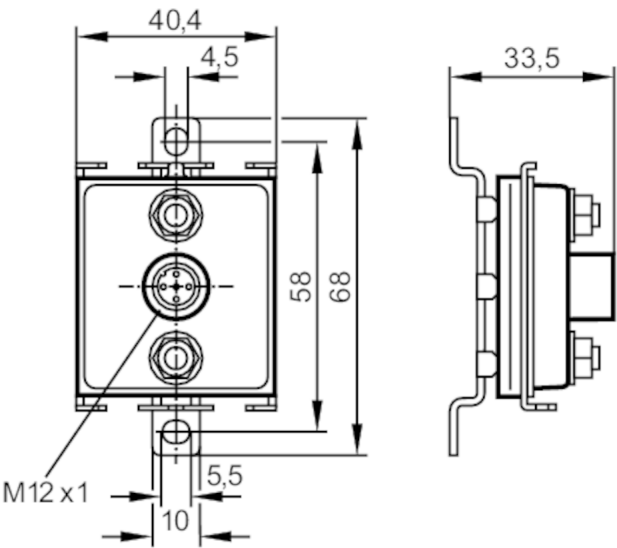

 
Data kelistrikan		
Tegangan pengoperasian	[V]	26.5...31.6 DC; (AS-i)
Kelas perlindungan		III
Tegangan pengoperasian AUX DC	[V]	18...32
Total beban arus maks.	[A]	4; (AS-i: 2 A; AUX: 2 A)
Output		
Desain kelistrikan		AS-i
Kondisi pengoperasian		
Suhu sekitar	[°C]	0...60
Catatan tentang suhu sekitar		-15...60 °C: hanya bersama dengan kabel EPDM
Kelembapan udara relatif maks.	[%]	80; (31 °C; penurunan linear hingga 50% (40 °C))
Ketinggian maks. di atas permukaan laut	[m]	2000
Perlindungan		IP 67; (jika digunakan di luar area berbahaya: IP 68 / IP 69K)
Tingkat kekotoran		2
Pengujian/persetujuan		
Tanda ATEX		Ex II 3G Ex ec IIC T6 Gc X
		Ex II 3D Ex tc IIIC T 70°C Dc X
Data teknis		
Berat	[g]	166.75
Material		komponen logam: baja tahan karat (1.4404 / 316L); gasket karet untuk pin kontak: FKM; Segel: EPDM
Torsi pengencangan	[Nm]	2.5; (mur pengunci)
Aksesori		
Aksesori (opsional)		Kunci torsi, E70390

E7354A



Konektor perpindahan isolasi kabel pipih AS-Interface

FCE Splitter ye/bk II 3D/3G

Keterangan	
Keterangan	Gunakan konektor M12 dengan mur segi enam
Jumlah paket	1 buah
Koneksi listrik - soket	
Konektor: 1 x M12; pengkodean: A; Torsi pengencangan: 1.2...1.4 Nm	
	
Koneksi	
1	AS-i +
2	0 V
3	AS-i -
4	+ 24 V
5	n. c.