


Bagian dinding

Wall passage standard

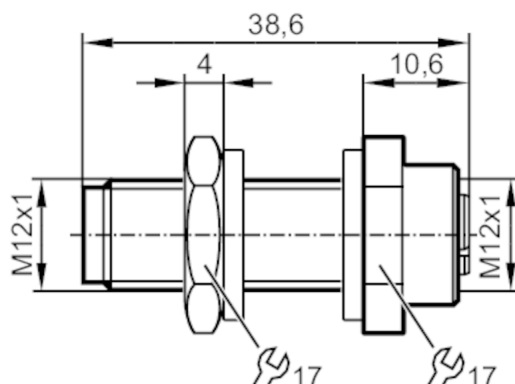

Data kelistrikan

Tegangan pengoperasian	[V]	< 60 AC/DC
Total beban arus maks.	[A]	8; (pin 1+3: 4 A; pin 2+4: 4 A)

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 65; IP 67

Data teknis


Berat	[g]	24.1
Material		kuningan berlapis nikel; Segel: FKM
Material bodi detakan		kuningan, berlapis nikel
Torsi pengencangan	[Nm]	1

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel

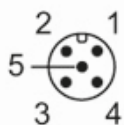




Bagian dinding

Wall passage standard

Koneksi

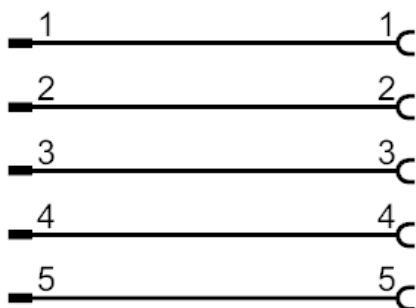

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel

