




Konektor perpindahan isolasi kabel pipih AS-Interface

FC Quick Connect M12 stainless

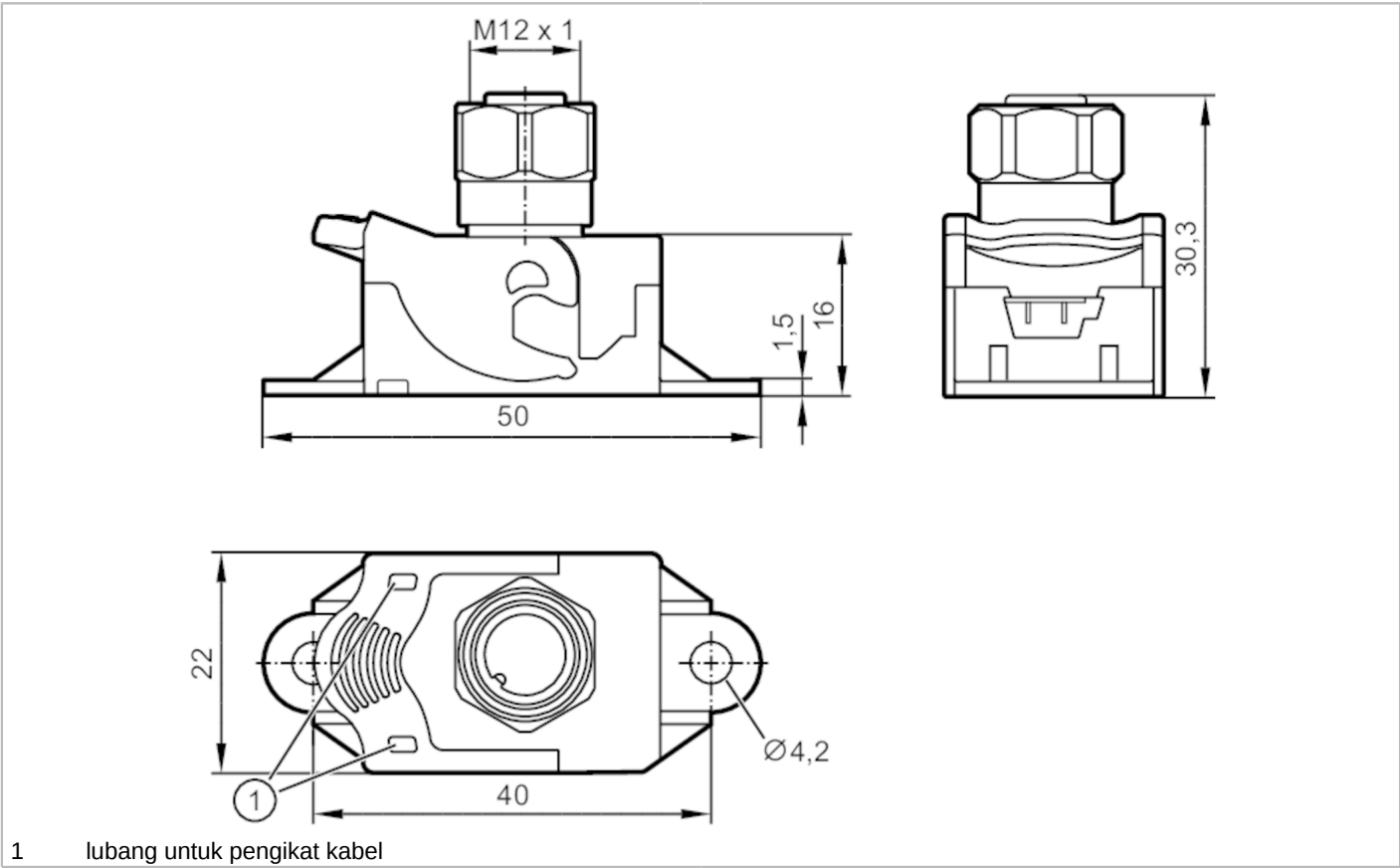

Data kelistrikan		
Tegangan pengoperasian	[V]	< 42 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...70
Suhu penyimpanan	[°C]	-25...75
Perlindungan		IP 67
Pengujian/persetujuan		
Persetujuan UL	suplai tegangan	Class 2
Data teknis		
Berat	[g]	18.45
Material		casing: PA; O-ring: EPDM; Mur pengunci: baja tahan karat (1.4305/303); pin kontak: perunggu dilapisi timah
Keterangan		
Keterangan		Kabel pipih tidak boleh berakhir di perangkat.
Jumlah paket		1 buah




Konektor perpindahan isolasi kabel pipih AS-Interface

FC Quick Connect M12 stainless

Koneksi listrik

Konektor: M12; pengkodean: A; Torsi pengencangan: 0.4...0.6 Nm

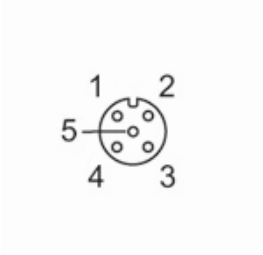

	ketika terhubung ke kabel pipih AS-i kuning
1	AS-i +
2	n.c.
3	AS-i -
4	n.c.
5	n.c.
	ketika terhubung ke kabel pipih hitam
1	AUX +
2	n.c.
3	AUX -
4	n.c.
5	n.c.