




Konektor perpindahan isolasi kabel pipih AS-Interface

FC Quick Connect M12

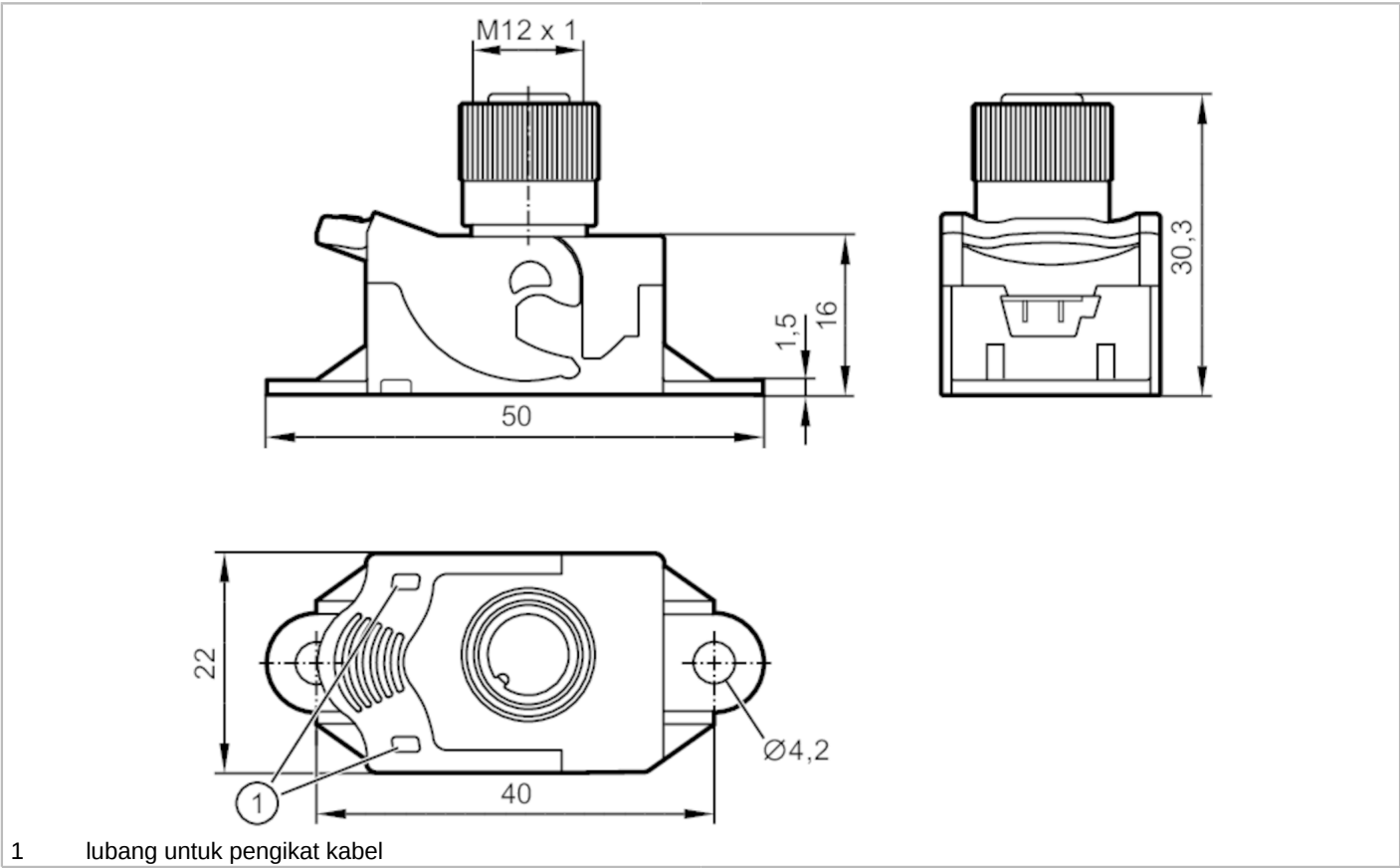


Data kelistrikan		
Tegangan pengoperasian	[V]	< 42 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...70
Suhu penyimpanan	[°C]	-25...75
Perlindungan		IP 67
Pengujian/persetujuan		
Persetujuan UL	suplai tegangan	Class 2
Data teknis		
Berat	[g]	17.7
Material		casing: PA; O-ring: FKM; Mur pengunci: kuningan berlapis nikel; pin kontak: perunggu dilapisi timah
Keterangan		
Keterangan		Kabel pipih tidak boleh berakhir di perangkat.
Jumlah paket		1 buah

**Konektor perpindahan isolasi kabel pipih AS-Interface**

FC Quick Connect M12

Koneksi listrik

Konektor: M12; pengkodean: A; Torsi pengencangan: 0.4...0.6 Nm

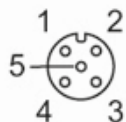

ketika terhubung ke kabel pipih AS-i kuning

1 AS-i +

2 n.c.

3 AS-i -

4 n.c.

5 n.c.

ketika terhubung ke kabel pipih hitam

1 AUX +

2 n.c.

3 AUX -

4 n.c.

5 n.c.