





Konektor perpindahan isolasi kabel pipih AS-Interface

FC connector, M12, V2A, 1m

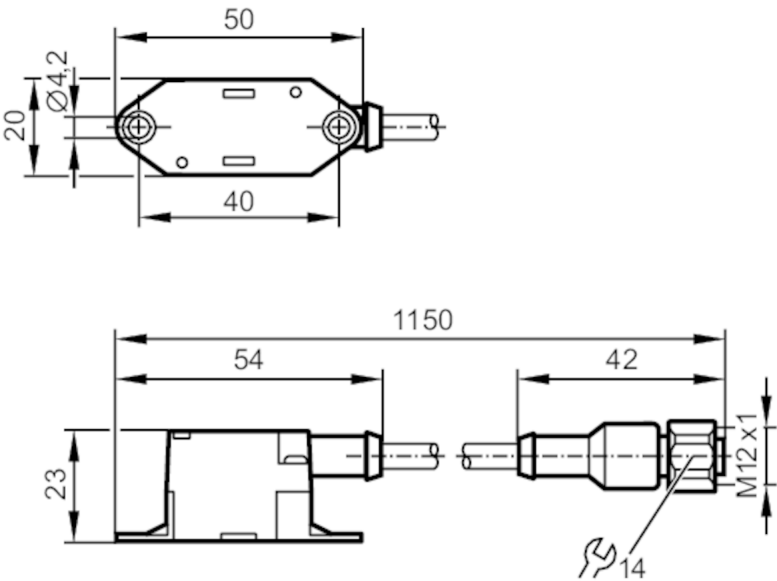

Aplikasi		
Fitur khusus		Kontak berlapis emas
Desain		AS-i
Data kelistrikan		
Tegangan pengoperasian	[V]	26.5...31.6 DC
Total beban arus maks.	[A]	2
Kondisi pengoperasian		
Suhu sekitar	[°C]	-20...70
Perlindungan		IP 67
Data teknis		
Berat	[g]	82.7
Material		casing bagian atas: PUR; casing bagian bawah: PA 6.6; sekrup: baja tahan karat (1.4305/303); Mur pengunci: baja tahan karat (1.4305/303)
Keterangan		
Keterangan		Kabel pipih tidak boleh berakhir di splitter. Gunakan segel kabel pipih atau tutup heat-shrink untuk penyegelan.
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 1 m, PVC, Ø 5.75 mm; 2 x 0.75 mm², PVC		

Konektor: M12, lurus; pengkodean: A; Kontak: dilapisi emas

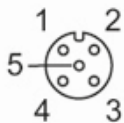


E79998



Konektor perpindahan isolasi kabel pipih AS-Interface

FC connector, M12, V2A, 1m

Koneksi

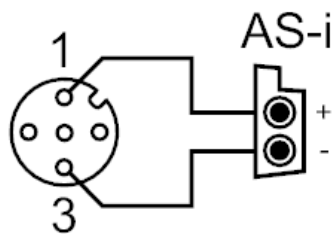

1	AS-i +
3	AS-i -