




Tag RFID

ID-TAG/D30x20/01

Produk tidak tersedia - entri arsip

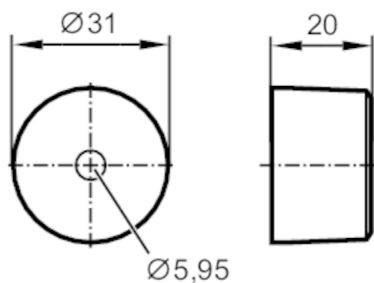

Aplikasi

Suhu pengoperasian (aktif)	[°C]	-25...85
----------------------------	------	----------

Data kelistrikan

Frekuensi pengoperasian	[MHz]	0,125
Ukuran memori	[bit]	363
Siklus pembacaan maks.		tidak terbatas
Siklus penulisan maks.		100000

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Suhu penyimpanan	[°C]	-25...180

Data teknis

Berat	[g]	23
Dimensi	[mm]	Ø 30 / L = 20
Material		PU

Keterangan

Keterangan	180 °C für max. 30 min Kumulierte Temperaturbeständigkeit ca. 100 h über 150 °C
Jumlah paket	1 buah