


Penghitung preset

COUNTER/210/LCD



1 klem

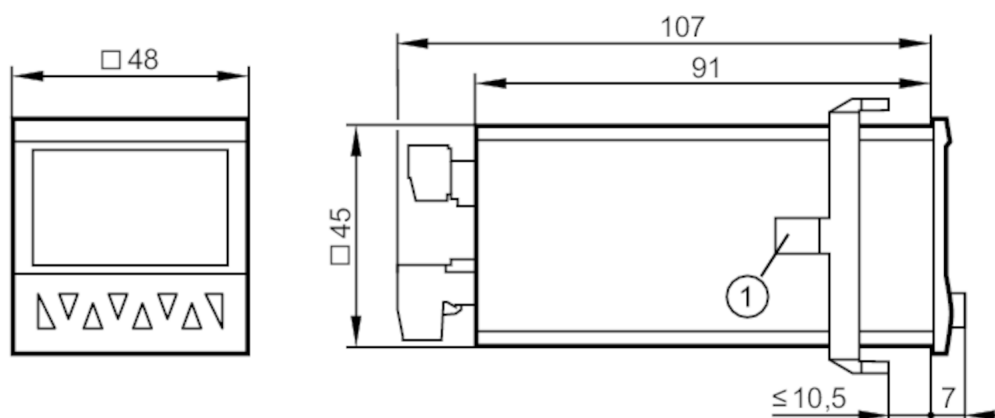

Karakteristik produk

Dimensi	[mm]	48 x 48 x 107
---------	------	---------------

Aplikasi

Aplikasi	penghitung preset dengan 2 preset
----------	-----------------------------------

Data kelistrikan

Tegangan nominal AC	[V]	90...260
Frekuensi nominal AC	[Hz]	50...60
Energi tambahan untuk sensor DC	[V]	24; (±15 %, 80 mA)

Input/output

Jumlah input dan output	Jumlah input digital: 2; Jumlah output relai: 2
-------------------------	---

Input

Jumlah input digital	2
----------------------	---

Output

Jumlah output relai	2
---------------------	---

Kondisi pengoperasian

Suhu sekitar	[°C]	-20...65
Suhu penyimpanan	[°C]	-25...75
Kelembapan udara relatif maks.	[%]	93
Perlindungan		IP 65; (di bagian depan)
Terminal peringkat perlindungan		IP 00

Pengujian/persetujuan

EME	EN 55011	kelas B
	EN 61000-6-2	(dengan kabel kontrol dan sinyal berpelindung)
Tahan guncangan	EN 60068-2-27	100 g XYZ
Ketahanan terhadap getaran	EN 60068-2-6	10...55 Hz / (1 mm / XYZ)



Penghitung preset

COUNTER/210/LCD

Data teknis		
Berat	[g]	214.5
Dimensi	[mm]	48 x 48 x 107
Material		PC hitam
Elemen display/pengoperasian		
Display		2 x display LCD 7 segmen, hijau berpenerangan 6 digit
Elemen pengoperasian	8	tombol tekan
Koneksi listrik		
terminal sekrup plug-in: 7 x ...2.5 mm ²		
terminal sekrup plug-in: 8 x ...1.5 mm ²		
Koneksi		

