




Kotak splitter

ZDO4H050MSS0000-00STAK120MSS

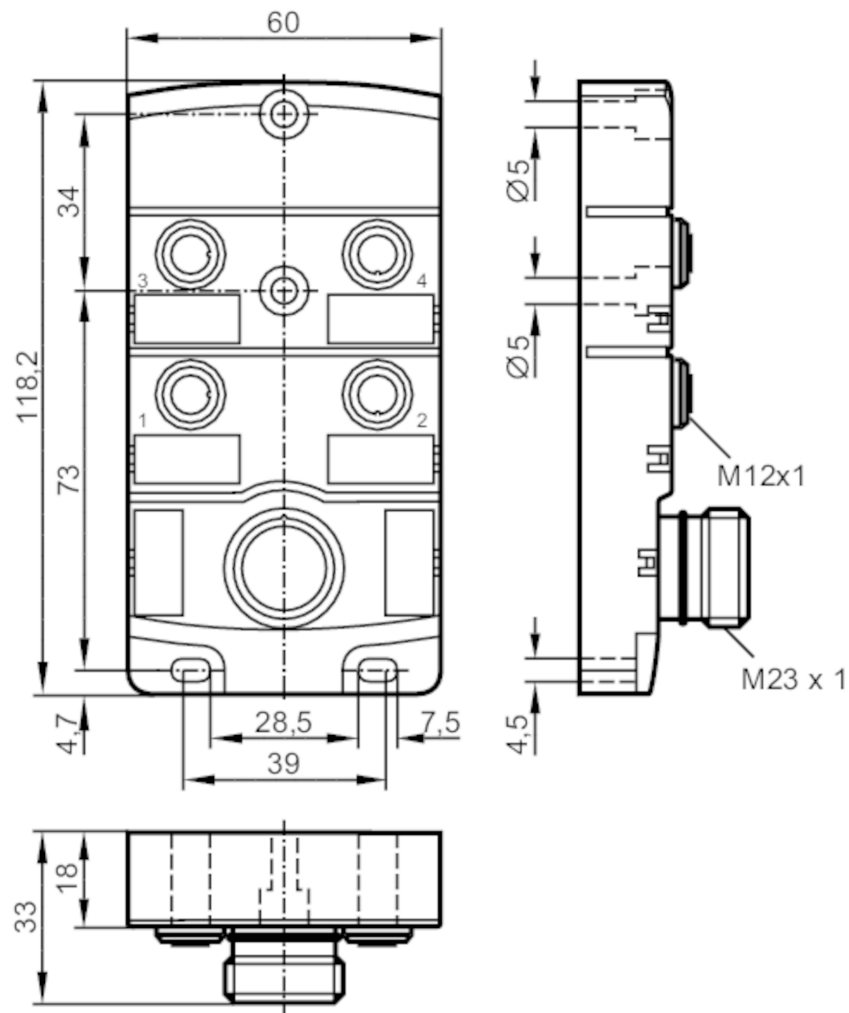

| Aplikasi                        |      |                                           |
|---------------------------------|------|-------------------------------------------|
| Fitur khusus                    |      | Bebas dari silikon; Kontak berlapis emas  |
| Bebas dari silikon              |      | ya                                        |
| Data kelistrikan                |      |                                           |
| Tegangan pengoperasian          | [V]  | < 30 DC; ("kelas suplai 2" menurut cULus) |
| Beban arus maks. per modul/slot | [A]  | 4                                         |
| Total beban arus maks.          | [A]  | 12                                        |
| Kondisi pengoperasian           |      |                                           |
| Suhu sekitar                    | [°C] | -25...80                                  |



## Kotak splitter

ZDO4H050MSS0000-00STAK120MSS

|              |       |
|--------------|-------|
| Perlindungan | IP 67 |
|--------------|-------|

## Pengujian/persetujuan

|                |              |        |
|----------------|--------------|--------|
| Persetujuan UL | Tipe penutup | Type 1 |
|----------------|--------------|--------|

## Data teknis

|                            |      |                 |
|----------------------------|------|-----------------|
| Berat                      | [g]  | 236.5           |
| Dimensi                    | [mm] | 33 x 60 x 118.2 |
| Material                   |      | PA              |
| Material bodi detakan      |      | PA              |
| Jumlah port kotak splitter |      | 4               |
| Tipe konektor              |      | M12             |

## Aksesori


|              |                    |
|--------------|--------------------|
| Item dikirim | Tutup pelindung: 2 |
|              | label: 4           |

## Keterangan


|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|

## Koneksi listrik - Koneksi

Konektor: 1 x M23; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

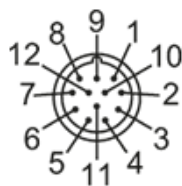

## Koneksi

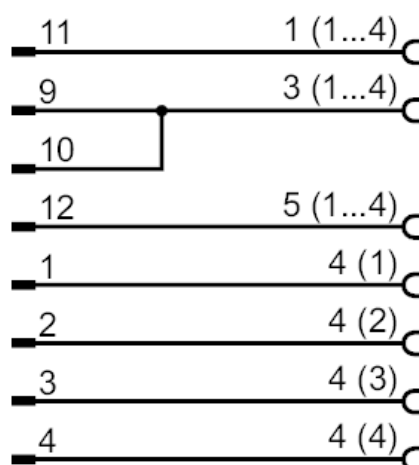



## Kotak splitter

ZDO4H050MSS0000-00STAK120MSS

### Koneksi listrik - slot

Konektor: 4 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

