




Kotak splitter

ZDO4H055MSS0000-00STAK120MSS

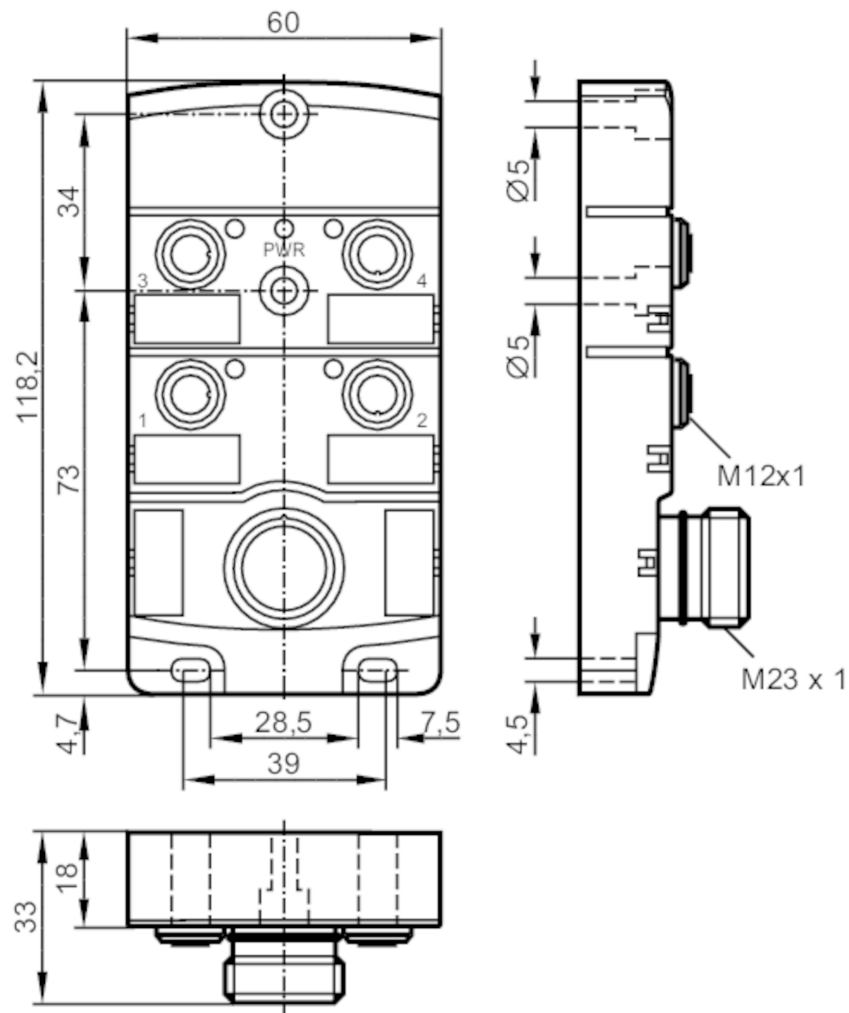

Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC; ("kelas suplai 2" menurut cULus)
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	10
Output		
Desain kelistrikan		PNP



Kotak splitter


ZDO4H055MSS0000-00STAK120MSS

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Pengujian/persetujuan		
Persetujuan UL	Tipe penutup	Type 1
Data teknis		
Berat	[g]	224.5
Dimensi	[mm]	33 x 60 x 118.2
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		4
Tipe konektor		M12
Elemen display/pengoperasian		
Display	status peralihan	4 x LED, kuning
	operasi	1 x LED, hijau
Aksesori		
Item dikirim	Tutup pelindung: 2	
	label: 4	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik - Koneksi		
Konektor: 1 x M23; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm		

Kotak splitter

ZDO4H055MSS0000-00STAK120MSS

Koneksi

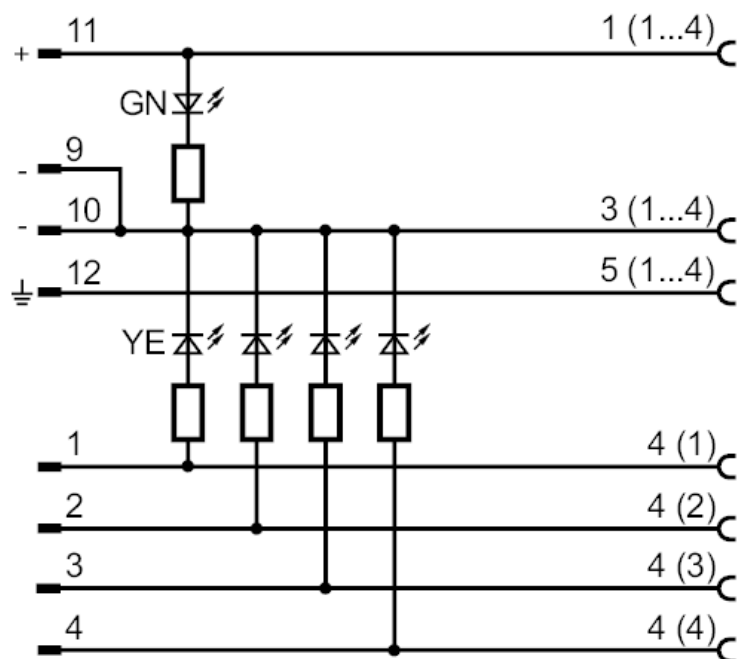

Koneksi listrik - slot

Konektor: 4 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

