




Kotak splitter

ZDO6H050MSS0000-00STAK190MSS

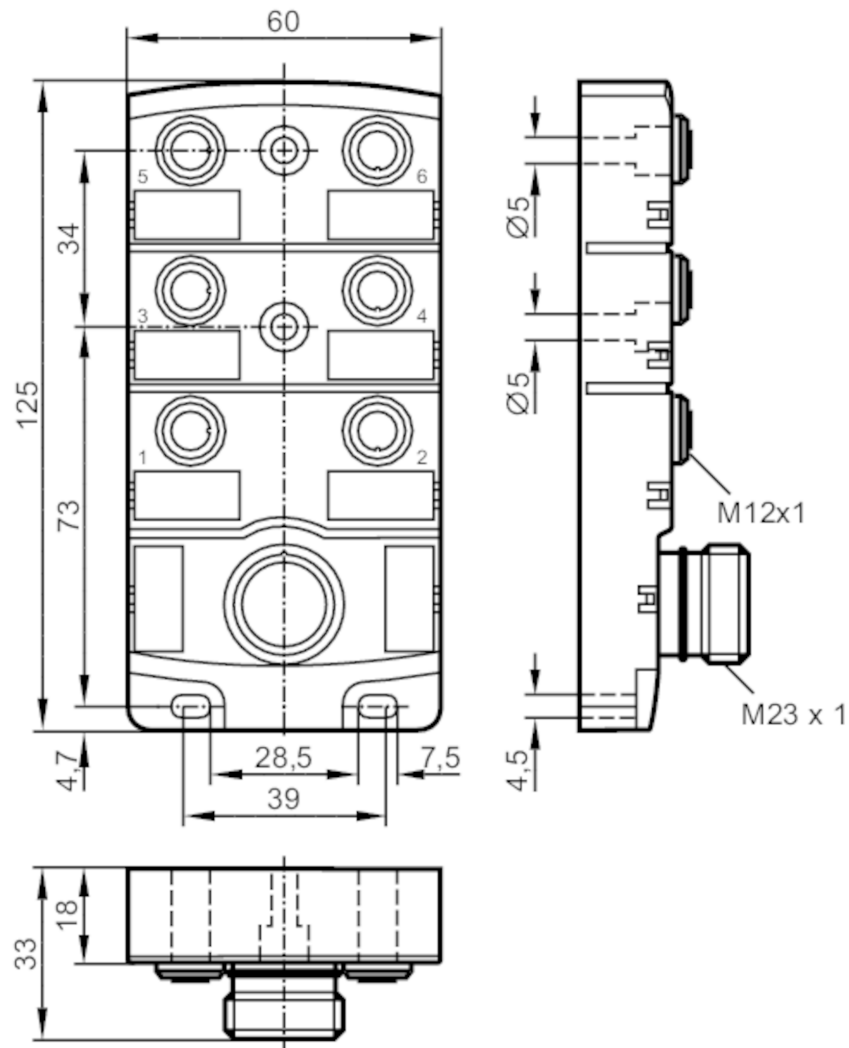

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
--------------	------	----------



Kotak splitter

ZDO6H050MSS0000-00STAK190MSS

Perlindungan	IP 67
--------------	-------

Pengujian/persetujuan

Persetujuan UL	Tipe penutup	Type 1
----------------	--------------	--------

Data teknis

Berat [g]	252.5
Material	PA
Material bodi detakan	PA
Jumlah port kotak splitter	6
Tipe konektor	M12

Aksesori


Item dikirim	Tutup pelindung: 2
	label: 6

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Koneksi

Konektor: 1 x M23; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

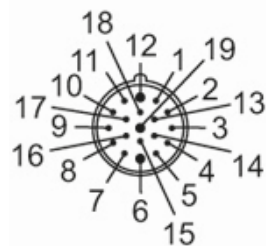

Koneksi

+	19	1 (1...6)
-	6	3 (1...6)
±	12	5 (1...6)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)
	17	4 (5)
	9	2 (5)
	2	4 (6)
	13	2 (6)



Kotak splitter

ZDO6H050MSS0000-00STAK190MSS

Koneksi listrik - slot

Konektor: 6 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

