




Kotak splitter

ZDO8H050MSS0000-00STAK120MSS

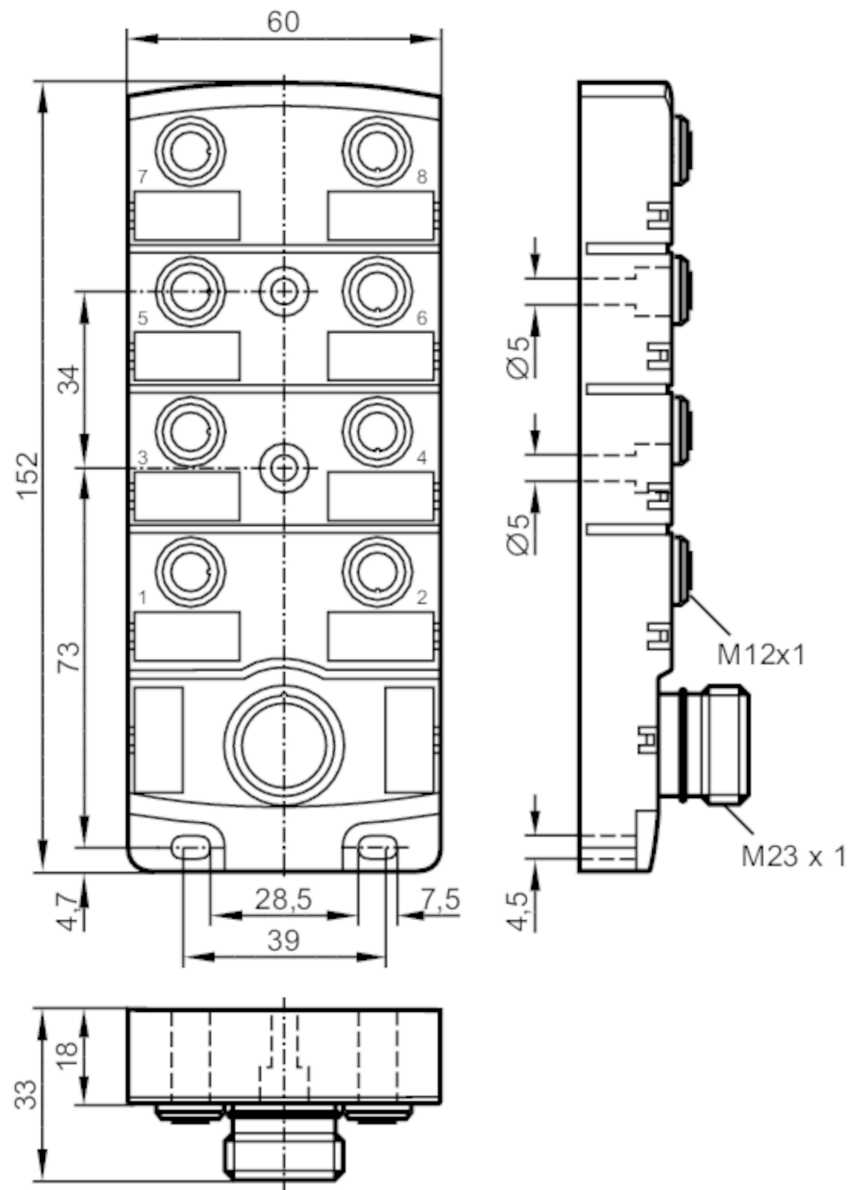

Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	12
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80



Kotak splitter

ZDO8H050MSS0000-00STAK120MSS

Perlindungan	IP 67
--------------	-------

Pengujian/persetujuan

Persetujuan UL	Tipe penutup	Type 1
----------------	--------------	--------

Data teknis

Berat	[g]	303.5
Dimensi	[mm]	33 x 60 x 152
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		8
Tipe konektor		M12

Aksesori


Item dikirim	Tutup pelindung: 2
	label: 8

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Koneksi

Konektor: 1 x M23; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

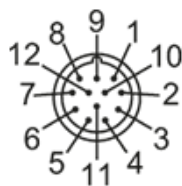

Koneksi

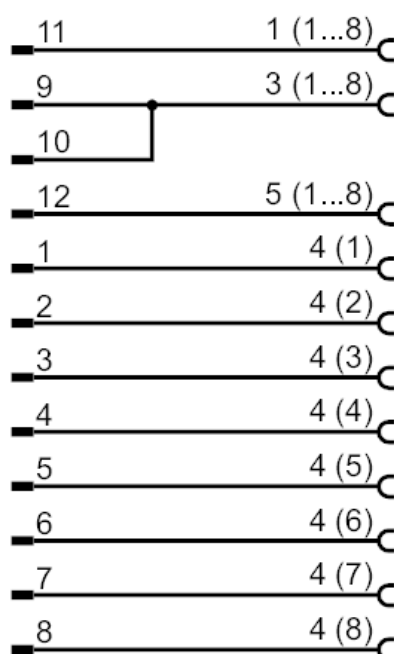



Kotak splitter

ZDO8H050MSS0000-00STAK120MSS

Koneksi listrik - slot

Konektor: 8 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

