




Kotak splitter

ZDO8H050MSS0000-00STAK190MSS

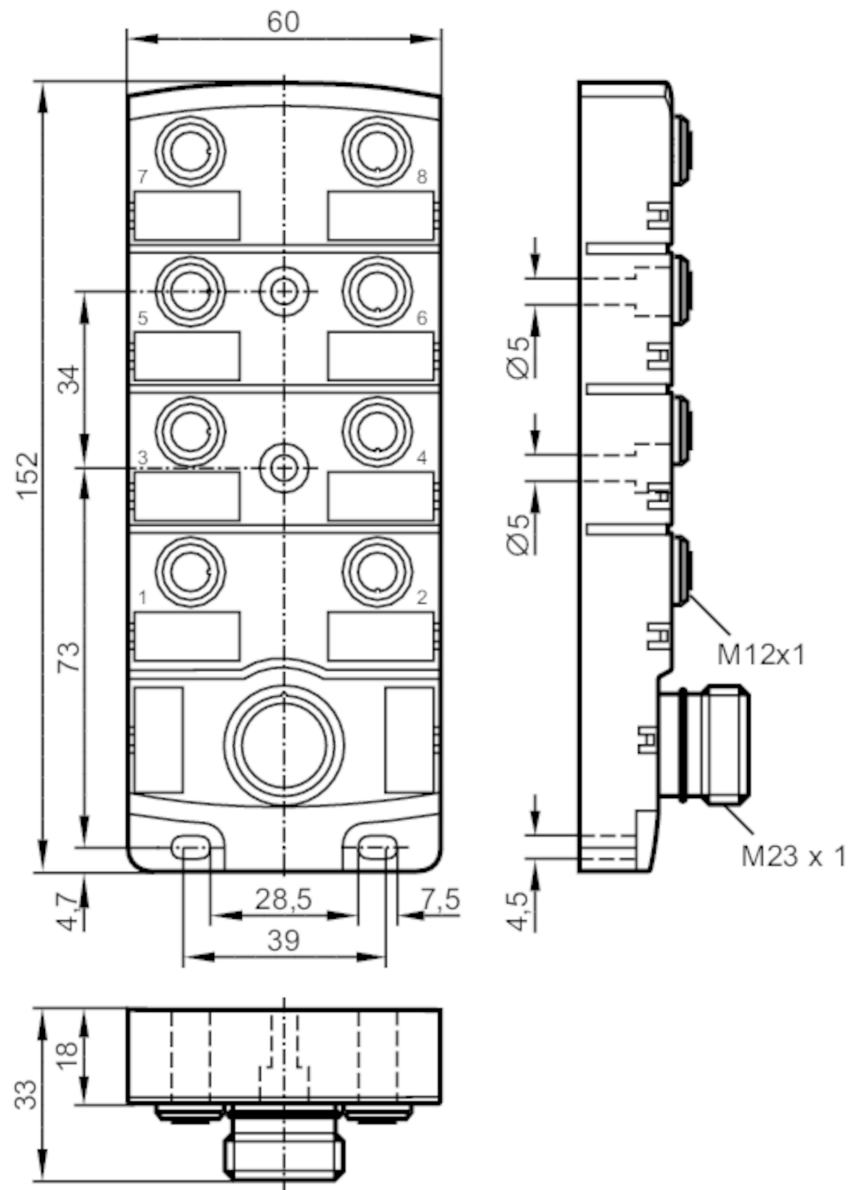

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	10

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...80
--------------	------	----------



Kotak splitter

ZDO8H050MSS0000-00STAK190MSS

Perlindungan	IP 67
--------------	-------

Pengujian/persetujuan

Persetujuan UL	Tipe penutup	Type 1
----------------	--------------	--------

Data teknis

Berat	[g]	303.5
Dimensi	[mm]	33 x 60 x 152
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		8
Tipe konektor		M12

Aksesori


Item dikirim	Tutup pelindung: 2
	label: 8

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Koneksi

Konektor: 1 x M23; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

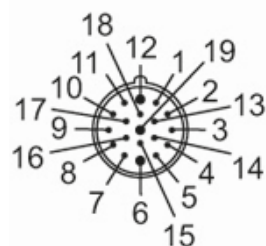

Koneksi

+	19	1 (1...8)
-	6	3 (1...8)
⊥	12	5 (1...8)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)
	17	4 (5)
	9	2 (5)
	2	4 (6)
	13	2 (6)
	11	4 (7)
	10	2 (7)
	1	4 (8)
	18	2 (8)



Kotak splitter

ZDO8H050MSS0000-00STAK190MSS

Koneksi listrik - slot

Konektor: 8 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

