



Kotak splitter

ZDO8H050MSS0005H11



Aplikasi		
Fitur khusus		Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60



Kotak splitter

ZDO8H050MSS0005H11

Perlindungan	IP 67; IP 68
--------------	--------------

Pengujian/persetujuan

Persetujuan UL	Tipe penutup	Type 1
----------------	--------------	--------

Data teknis

Berat	[g]	683.5
Dimensi	[mm]	22 x 54 x 127
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		8
Tipe konektor		M12
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	siklus pembengkokan	> 2 Mio.

Aksesori

Item dikirim	Tutup pelindung: 2
	label: 8

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 8.2 mm; 8 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 1 mm² (95 x Ø 0.1 mm)

Koneksi listrik - slot

Konektor: 8 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

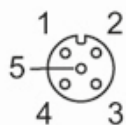



Kotak splitter

ZDO8H050MSS0005H11

Koneksi

BN	1 (1...8)
BU	3 (1...8)
GN/YE	5 (1...8)
WH	4 (1)
GN	4 (2)
YE	4 (3)
GY	4 (4)
PK	4 (5)
RD	4 (6)
BK	4 (7)
VT	4 (8)

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning