




Kotak splitter

ZDO8H05HMSS0005H19

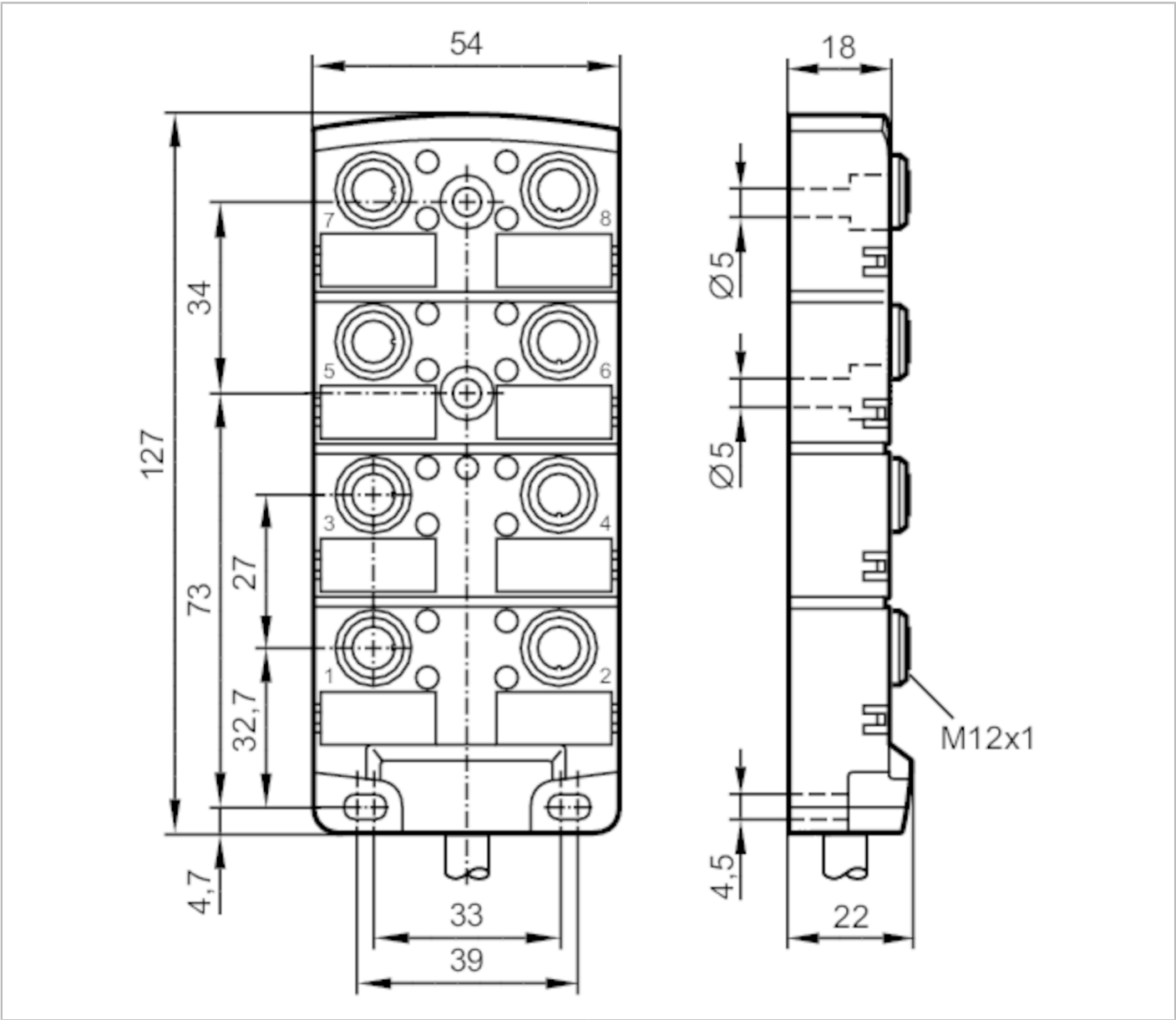


Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12
Output		
Desain kelistrikan	PNP	



Kotak splitter

ZDO8H05HMSS0005H19


Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan	IP 67; IP 68	
Pengujian/persetujuan		
Persetujuan UL	Tipe penutup	Type 1
Data teknis		
Berat	[g]	899
Dimensi	[mm]	22 x 54 x 127
Material	PA	
Material bodi detakan	PA	
Jumlah port kotak splitter	8	
Tipe konektor	M12	
Kesesuaian rantai tarik	ya	
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	siklus pembengkokan	> 2 Mio.
Elemen display/pengoperasian		
Display	status peralihan	16 x LED, kuning
	operasi	1 x LED, hijau
Aksesori		
Item dikirim	Tutup pelindung: 2 label: 8	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 9.7 mm; 16 x 0.34 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)		
Koneksi listrik - slot		
Konektor: 8 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm		

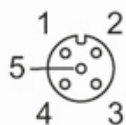

Kotak splitter

ZDO8H05HMSS0005H19

Koneksi

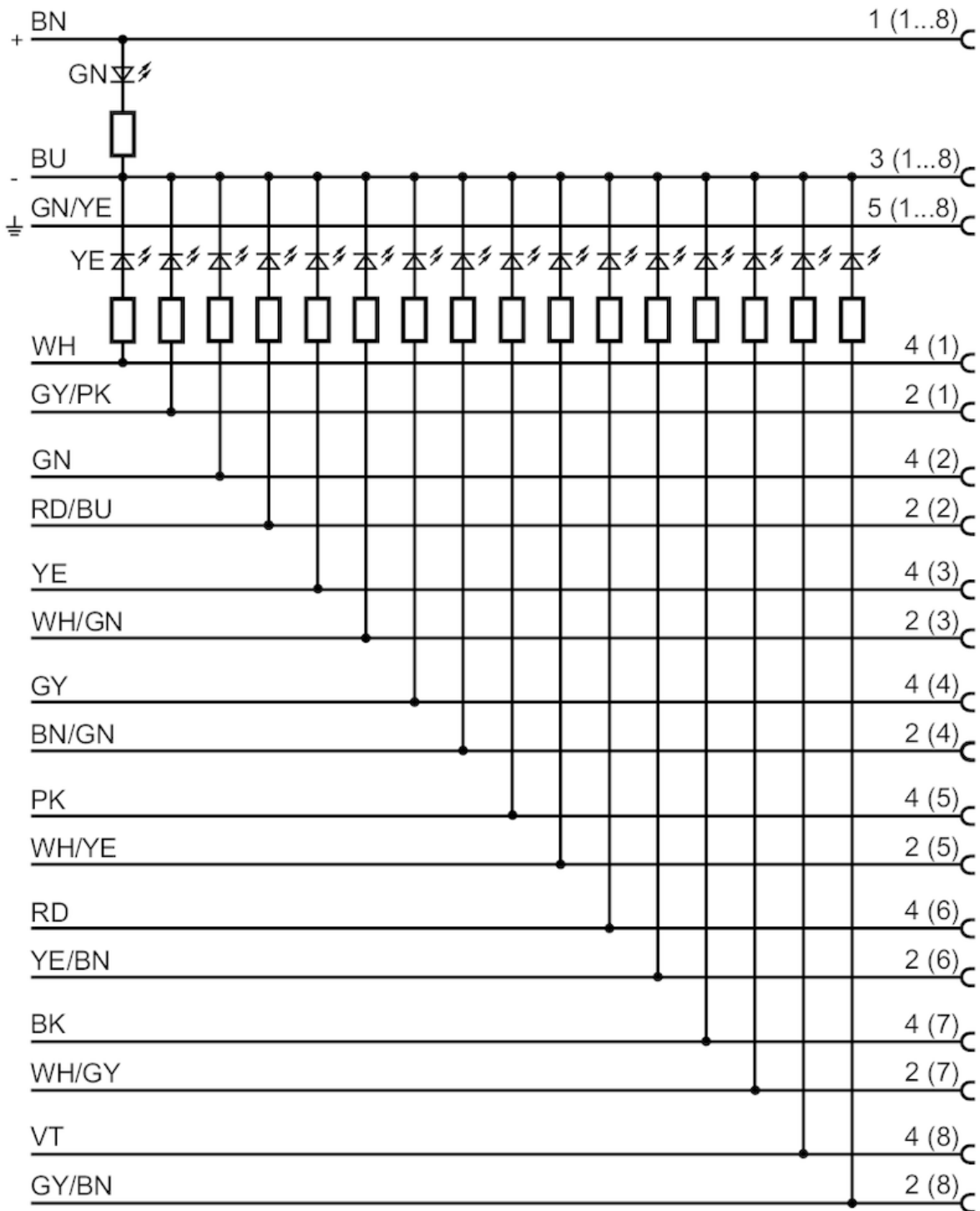

Warna core :

BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning

EBC024

Kotak splitter

ZDO8H05HMSS0005H19

