

Kotak splitter

ZDO4H050MSS0010H07



Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan	II
Beban arus maks. per modul/ slot [A]	4
Total beban arus maks. [A]	12

Kondisi pengoperasian

Suhu sekitar [°C]	-25...80
Suhu sekitar (bergerak) [°C]	-5...60
Perlindungan	IP 67; IP 68

Data teknis

Berat [g]	937
Dimensi [mm]	18 x 54 x 82
Material	PA
Material bodi detakan	PA



Kotak splitter

ZDO4H050MSS0010H07

Jumlah port kotak splitter	4	
Tipe konektor	M12	
Kesesuaian rantai tarik	ya	
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	siklus pembengkokan	> 2 Mio.

Aksesori

Item dikirim	Tutup pelindung: 2
	label: 4

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 7.5 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 1 mm² (55 x Ø 0.15 mm)

Koneksi listrik - slot

Konektor: 4 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

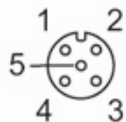



Kotak splitter

ZDO4H050MSS0010H07

Koneksi

BN	1 (1...4)
BU	3 (1...4)
GN/YE	5 (1...4)
WH	4 (1)
GN	4 (2)
YE	4 (3)
GY	4 (4)

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
WH =	putih
YE =	kuning