

Kotak splitter

ZDO6H050MSS0010H15



Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan	II
Beban arus maks. per modul/slot [A]	4
Total beban arus maks. [A]	12

Kondisi pengoperasian

Suhu sekitar [°C]	-25...80
Suhu sekitar (bergerak) [°C]	-5...60
Perlindungan	IP 67; IP 68

Data teknis

Berat [g]	1332
-----------	------



Kotak splitter

ZDO6H050MSS0010H15

Dimensi	[mm]	22 x 54 x 100
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		6
Tipe konektor		M12
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	siklus pembengkokan	> 2 Mio.
	ketegangan torsional	maksimum 30 °/m

Aksesori

Item dikirim	Tutup pelindung: 2
	label: 6

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 8.8 mm; 12 x 0.34 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Koneksi listrik - slot

Konektor: 6 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

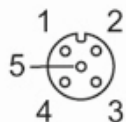



Kotak splitter

ZDO6H050MSS0010H15

Koneksi

<u>BN</u>	1 (1...6)	C
<u>BU</u>	3 (1...6)	C
<u>GN/YE</u>	5 (1...6)	C
<u>GY/PK</u>	2 (1)	C
<u>RD/BU</u>	2 (2)	C
<u>WH/GN</u>	2 (3)	C
<u>BN/GN</u>	2 (4)	C
<u>WH/YE</u>	2 (5)	C
<u>YE/BN</u>	2 (6)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning