




Kotak splitter

ZDO8H05HMSS0010H19

 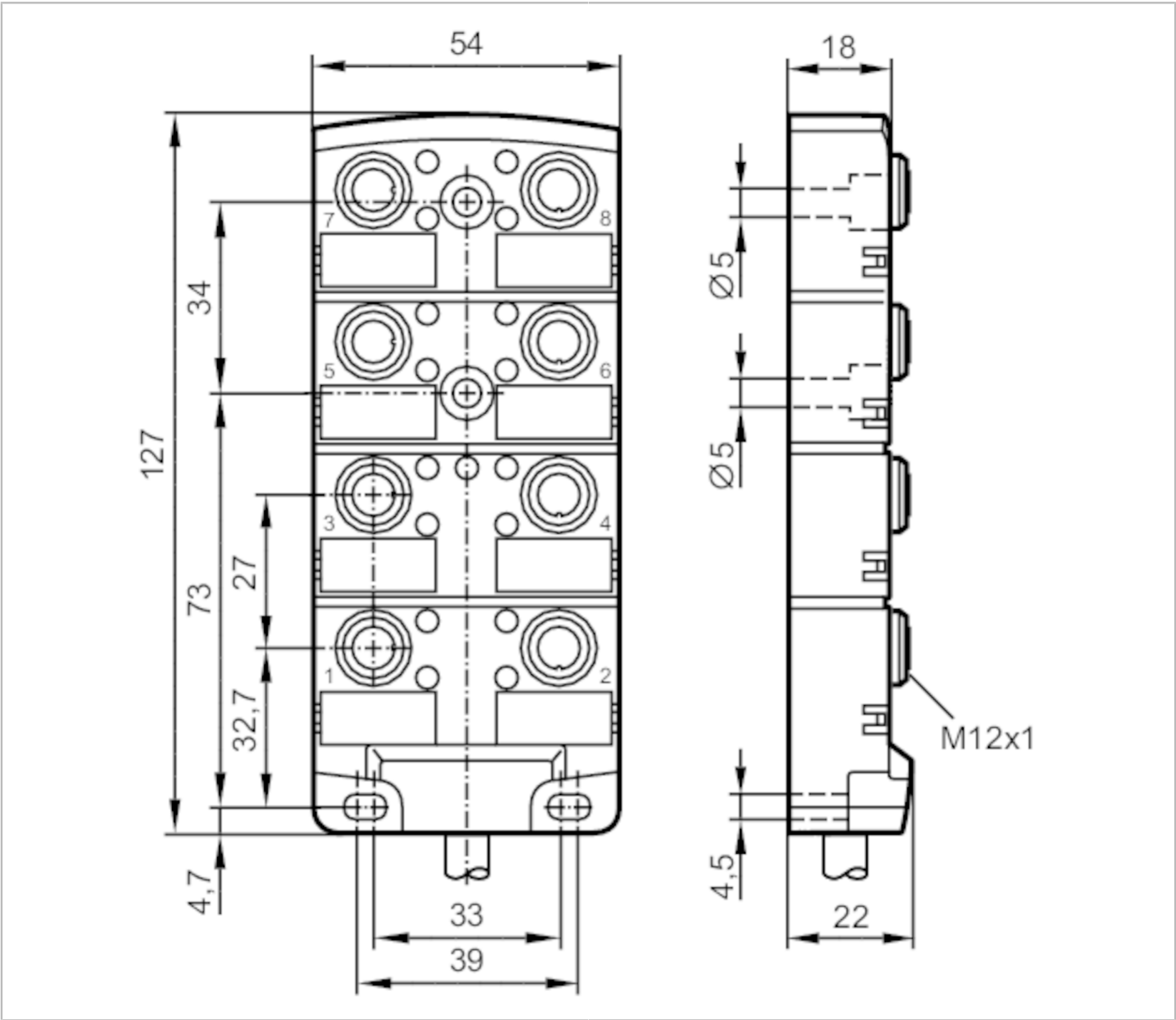


Aplikasi	
Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya
Data kelistrikan	
Tegangan pengoperasian [V]	10...30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan	II
Beban arus maks. per modul/ slot [A]	4
Total beban arus maks. [A]	12
Output	
Desain kelistrikan	PNP



Kotak splitter

ZDO8H05HMSS0010H19

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan		IP 67; IP 68
Data teknis		
Berat	[g]	1191.6
Dimensi	[mm]	22 x 54 x 127
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		8
Tipe konektor		M12
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	siklus pembengkokan	> 2 Mio.
Elemen display/pengoperasian		
Display	status peralihan	16 x LED, kuning
	operasi	1 x LED, hijau
Aksesori		
Item dikirim	Tutup pelindung: 2	
	label: 8	
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 9.7 mm; 16 x 0.34 mm ² (63 x Ø 0.1 mm) + 3 x 1.0 mm ² (127 x Ø 0.1 mm)		
Koneksi listrik - slot		
Konektor: 8 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm		
		

Kotak splitter

ZDO8H05HMSS0010H19

Koneksi



Warna core :

BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning

EBC036

Kotak splitter

ZDO8H05HMSS0010H19

