


ZDO6H057MSS00,5H09

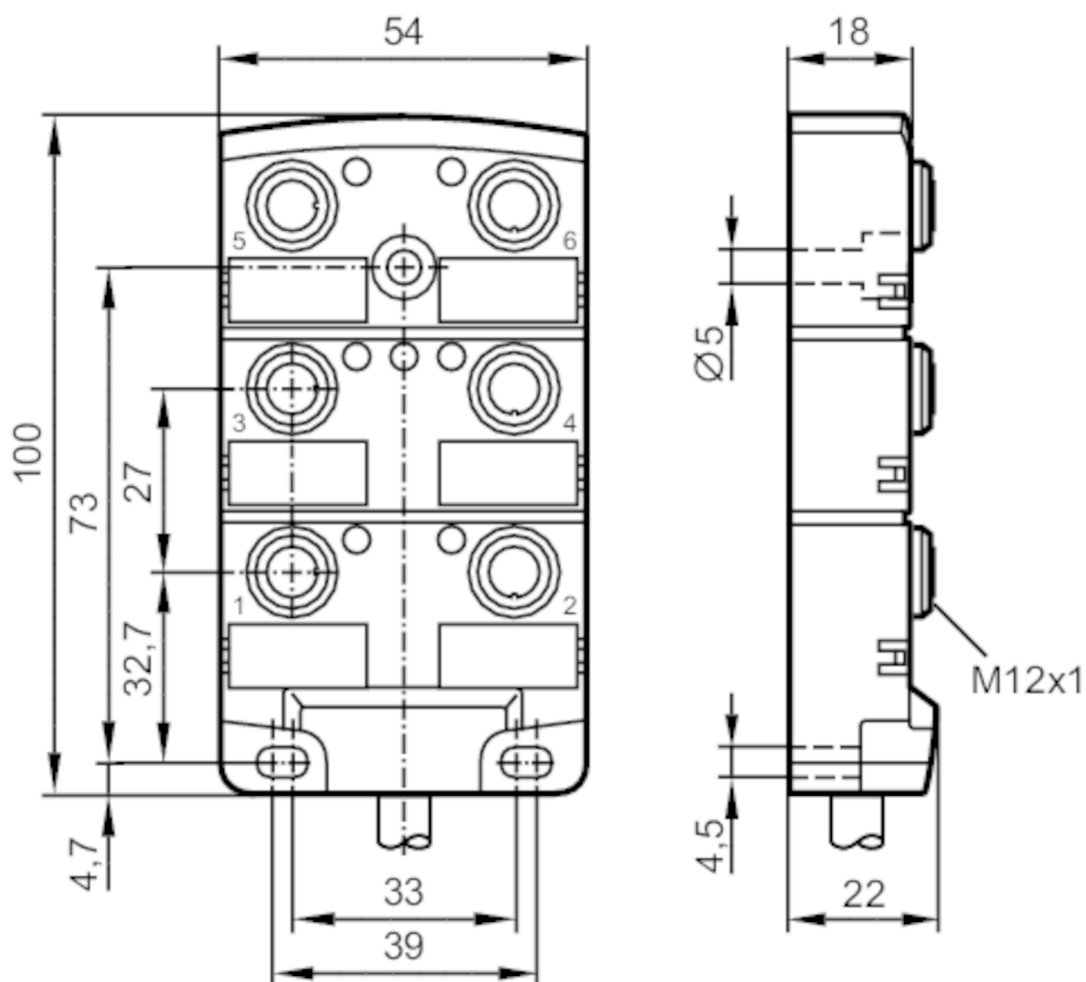

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik
Bebas dari silikon	ya

Tegangan pengoperasian	[M]	10...30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12


Desain kelistrikan	PNP
--------------------	-----

Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan		IP 67; IP 68



Kotak splitter

ZDO6H057MSS00,5H09

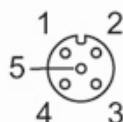
Data teknis		
Berat	[g]	212.7
Dimensi	[mm]	22 x 54 x 100
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		6
Tipe konektor		M12
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	siklus pembengkokan	> 2 Mio.
Elemen display/pengoperasian		
Display	status peralihan	6 x LED, kuning
	operasi	1 x LED, hijau
Aksesori		
Item dikirim	Tutup pelindung: 2	
	label: 6	
Keterangan		
Jumlah paket	1 buah	
Koneksi listrik		
Kabel: 0.5 m, PUR, Bebas halogen, hitam, Ø 7.8 mm; 6 x 0.34 mm² (43 x Ø 0.1 mm) + 3 x 1 mm² (55 x Ø 0.15 mm)		
Koneksi listrik - slot		
Konektor: 6 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm		
		



Kotak splitter

ZDO6H057MSS00,5H09

Koneksi

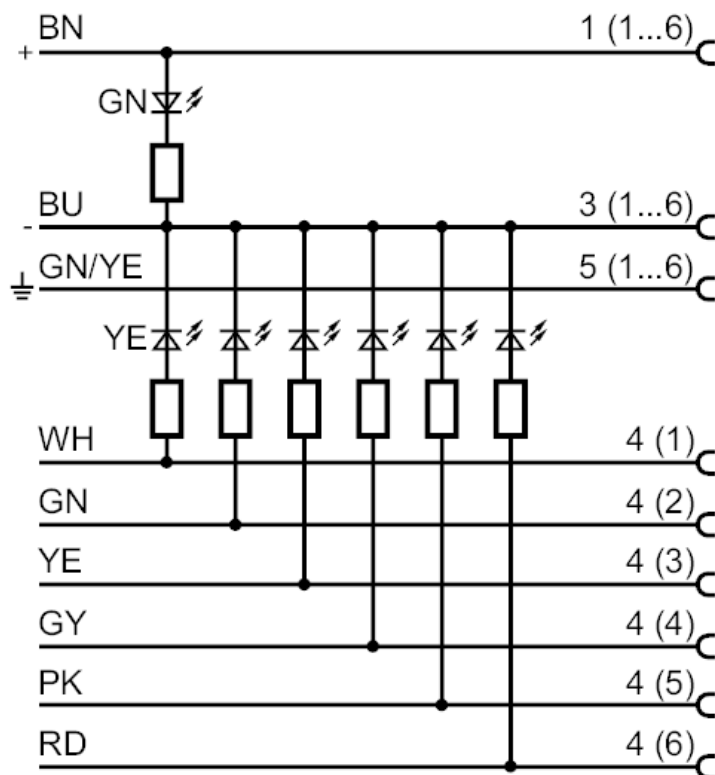

BN =	Warna core :	coklat
BU =		biru
GN =		hijau
GN/YE =		hijau/kuning
GY =		abu-abu
PK =		merah muda
RD =		merah
WH =		putih
YE =		kuning