




Kotak splitter

ZDO6H050MSS0010E15

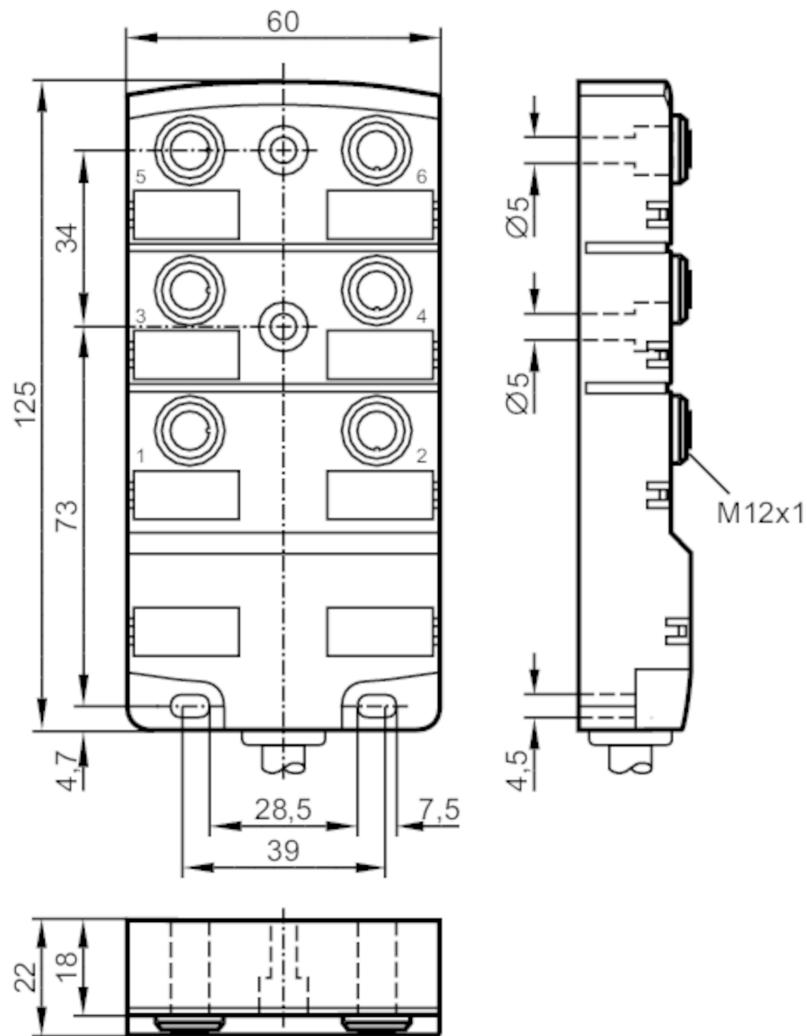

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 DC; ("kelas suplai 2" menurut cULus)
Beban arus maks. per modul/ slot	[A]	4; (per pin: 2; per grup: 8)
Total beban arus maks.	[A]	12

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...40
Suhu sekitar (bergerak)	[°C]	-5...60



Kotak splitter

ZDO6H050MSS0010E15

Perlindungan	IP 67
--------------	-------

Pengujian/persetujuan

Persetujuan UL	Tipe penutup	Type 1
----------------	--------------	--------

Data teknis

Berat	[g]	880
Dimensi	[mm]	22 x 60 x 125
Material		PA
Material bodi detakan		PA
Jumlah port kotak splitter		6
Tipe konektor		M12

Aksesori

Item dikirim	label: 6
--------------	----------

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 10 m, PVC, hitam, Ø 6.3 mm; 5 x 0.5 mm²

Koneksi listrik - slot

Konektor: 6 x M12; pengkodean: A; Bodi cetakan: PA; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

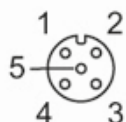




Kotak splitter

ZDO6H050MSS0010E15

Koneksi

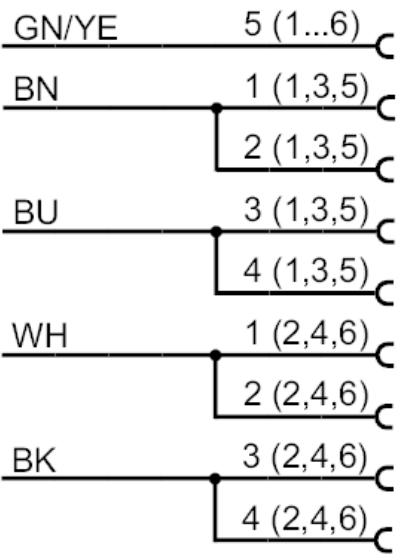

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN/YE =	hijau/kuning
WH =	putih