


Kotak splitter

ZDO4F035MSS0000-STGH120MSS

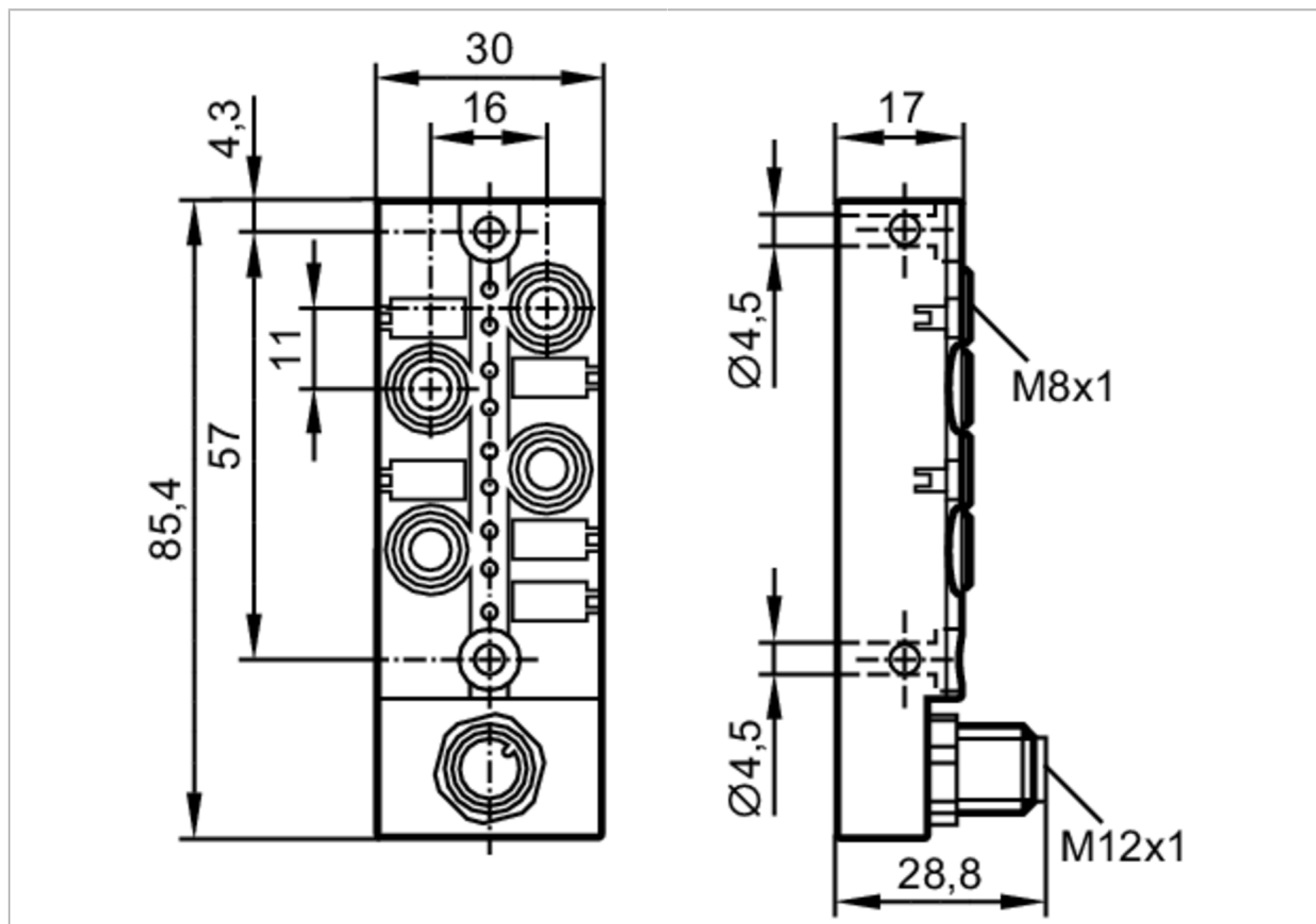

Aplikasi		
Fitur khusus		Kontak berlapis emas
Data kelistrikan		
Tegangan pengoperasian	[V]	15...30 DC
Kelas perlindungan		III
Beban arus maks. per modul/slot	[A]	1
Total beban arus maks.	[A]	1
Output		
Desain kelistrikan		PNP
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan		IP 67
Data teknis		
Berat	[g]	86.8
Dimensi	[mm]	17 x 30 x 85.4
Material		PBT-GF20; kuningan berlapis nikel

Kotak splitter

ZDO4F035MSS0000-STGH120MSS

Material bodi detakan	PBT-GF 20 / kuningan, berlapis nikel
Jumlah port kotak splitter	4
Tipe konektor	M8

Elemen display/pengoperasian


Display	status peralihan	4 x LED, kuning
	operasi	1 x LED, hijau

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Koneksi

Konektor: 1 x M12; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

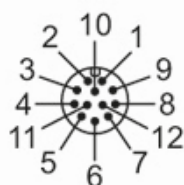

Koneksi

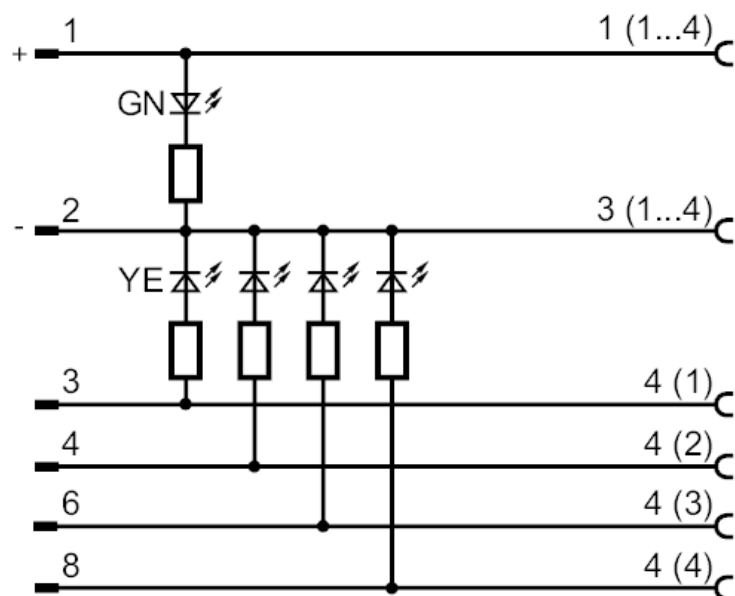



Kotak splitter

ZDO4F035MSS0000-STGH120MSS

Koneksi listrik - slot

Konektor: 4 x M8; pengkodean: A; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

