


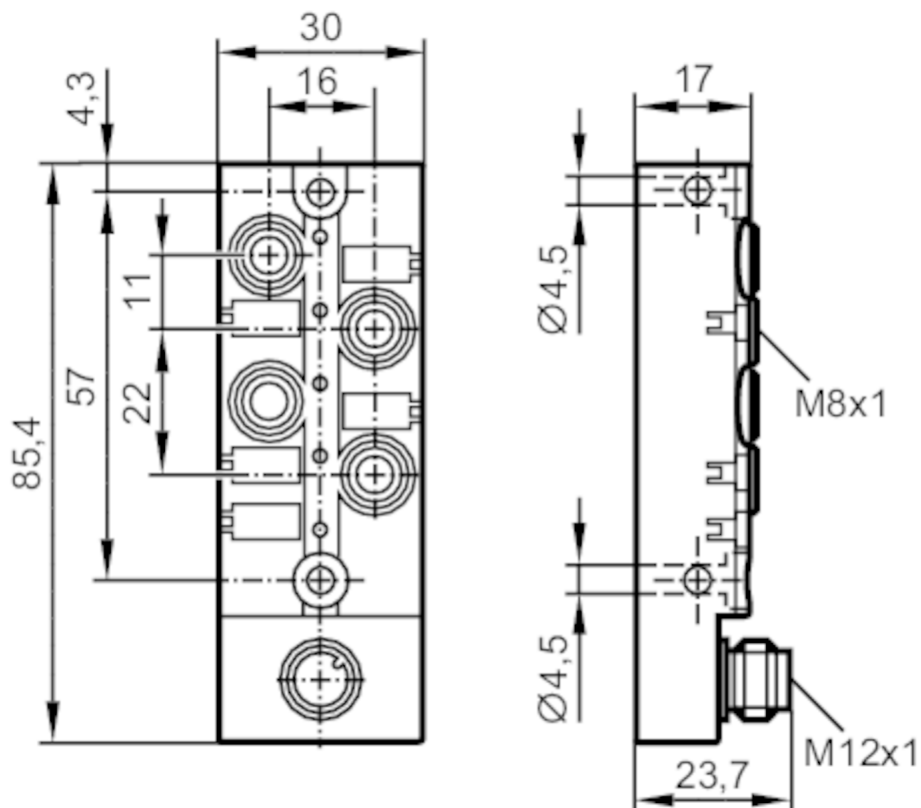

Kotak splitter

ZDO4F035MSJ0000---STGH080MSJ



Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC; ("kelas suplai 2" menurut cULus)

Kelas perlindungan III

Beban arus maks. per modul/ slot [A] 2

Total beban arus maks. [A] 2

Output

Desain kelistrikan NPN

Kondisi pengoperasian

Suhu sekitar [°C] -25...80

Suhu sekitar (bergerak) [°C] -5...60

Perlindungan IP 65; IP 67; IP 68; (1 m / 7 hari)

Data teknis

Berat [g] 88

Dimensi [mm] 23.7 x 30 x 85.4

Material PBT-GF20; kuningan berlapis nikel

Material bodi detakan PBT-GF 20 / kuningan, berlapis nikel

Jumlah port kotak splitter 4

Kotak splitter

ZDO4F035MSJ0000---STGH080MSJ

Tipe konektor	M8
---------------	----

Elemen display/pengoperasian

Display	status peralihan	4 x LED, kuning
	operasi	1 x LED, hijau

Aksesori


Aksesori (opsional)	Adaptor rel DIN: E73006
	Tutup pelindung: M8, E73005

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Koneksi

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas

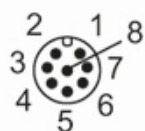

Koneksi

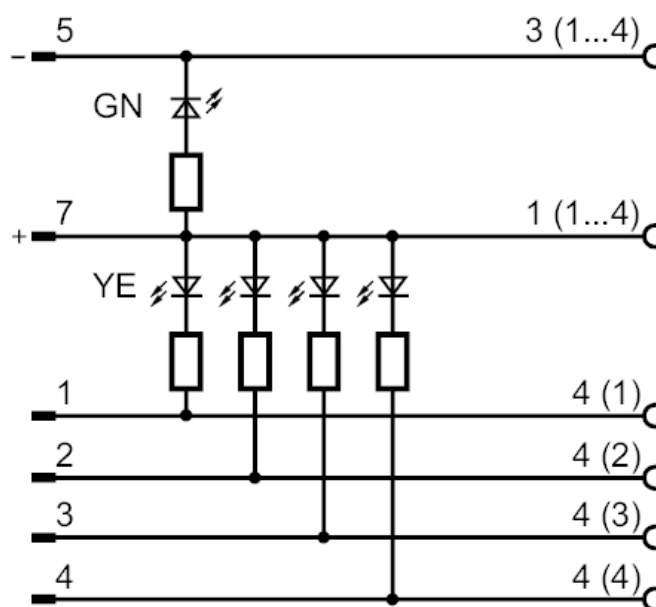



Kotak splitter

ZDO4F035MSJ0000---STGH080MSJ

Koneksi listrik - slot

Konektor: 4 x M8; pengkodean: A; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas

