


Splitter Y

ZDO2H050MSS0000-00STGH050MSS

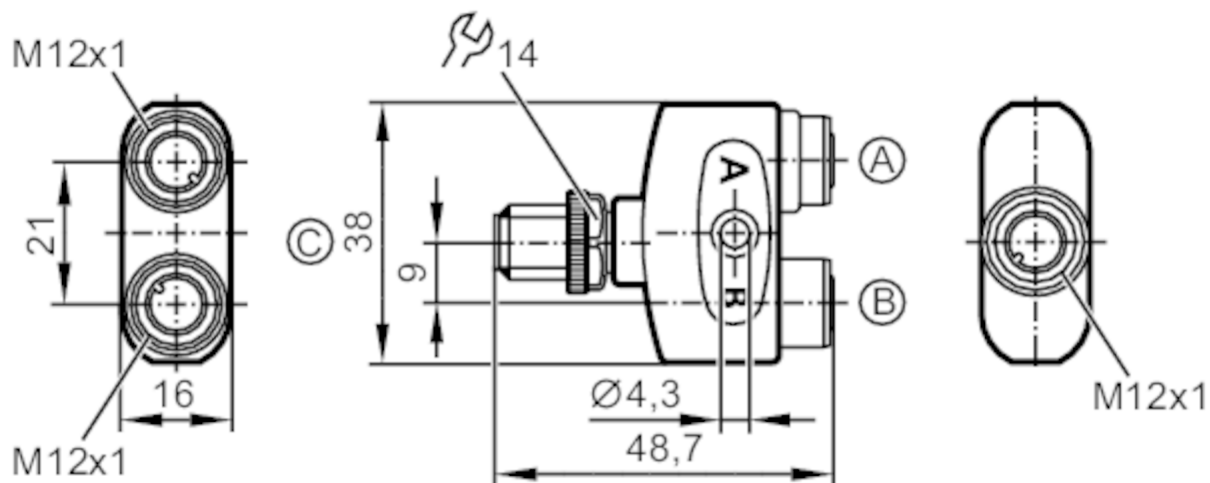

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Aplikasi	fungsi logic OR
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 60 AC/DC; (cULus: 30 AC / 42 DC)
Kelas perlindungan	II
Beban arus maks. per modul/slot [A]	4
Total beban arus maks. [A]	4
Peringkat arus keseluruhan (UL) [A]	3

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
Catatan tentang suhu sekitar	cULus: ...65 °C
Suhu penyimpanan [°C]	-25...55
Kelembapan penyimpanan [%]	10...100
Kondisi cuaca lainnya untuk penyimpanan sesuai dengan kelas yang dinyatakan	1K22/ DIN 60721-3-1
Perlindungan	IP 65; IP 67; IP 68; IP 69K

Data teknis

Berat [g]	36.9
Material	casing: PA oranye; Segel: FKM
Material mur	kuningan, berlapis nikel



Splitter Y

ZDO2H050MSS0000-00STGH050MSS


Keterangan

Jumlah paket


1 buah

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

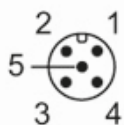

Koneksi

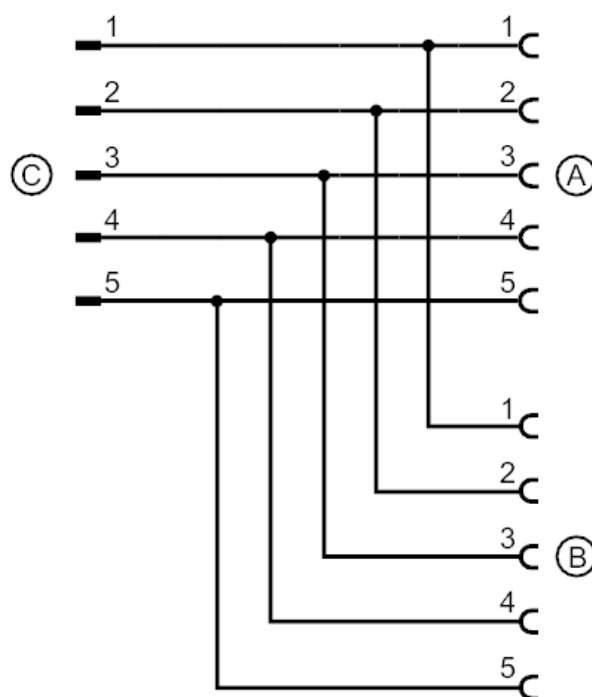

Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

