

ZDO8F039MSS0000---STGH120MSS



Kontak berlapis emas

Tegangan pengoperasian	[V]	15...30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan		III
Beban arus maks. per modul/ slot	[A]	2
Total beban arus maks.	[A]	2

PNP

Suhu sekitar	[°C]	-25...80
--------------	------	----------



Kotak splitter

ZDO8F039MSS0000---STGH120MSS

Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan	IP 67; IP 68; (1 m / 7 hari)	

Data teknis

Berat	[g]	128.5
Material	PBT-GF20; kuningan berlapis nikel	
Material bodi detakan	PBT-GF 20 / kuningan, berlapis nikel	
Jumlah port kotak splitter	8	
Tipe konektor	M8	

Elemen display/pengoperasian

Display	status peralihan	8 x LED, kuning
	operasi	1 x LED, hijau

Aksesori


Aksesori (opsional)	Tutup pelindung: M8, E73005
---------------------	-----------------------------

Keterangan

Jumlah paket	1 buah
--------------	--------

Koneksi listrik - Koneksi


Konektor: 1 x M12; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

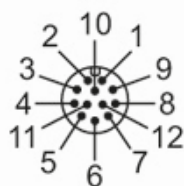

Kotak splitter

ZDO8F039MSS0000---STGH120MSS

Koneksi

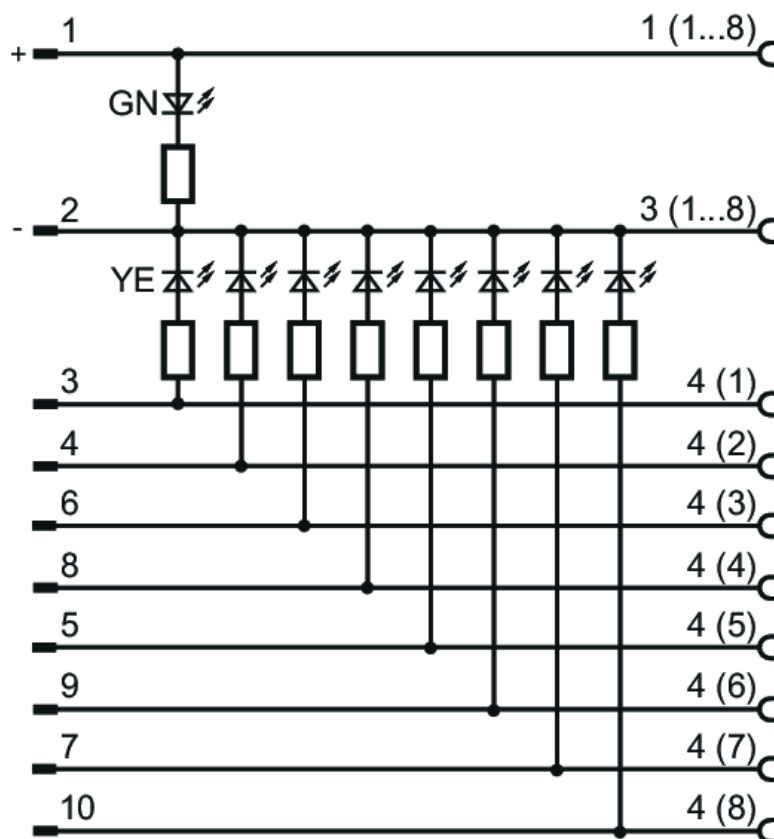

Koneksi listrik - slot

Konektor: 8 x M8; pengkodean: A; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

