


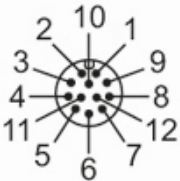

Kotak splitter


ZDOAF03BMSS0000---STGH120MSS

Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan		IP 67; IP 68; (1 m / 7 hari)
Data teknis		
Berat	[g]	150.5
Material		PBT-GF20; kuningan berlapis nikel
Material bodi detakan		PBT-GF 20 / kuningan, berlapis nikel
Jumlah port kotak splitter		10
Tipe konektor		M8
Elemen display/pengoperasian		
Display	status peralihan	10 x LED, kuning
	operasi	1 x LED, hijau
Aksesori		
Aksesori (opsional)		Tutup pelindung: M8, E73005
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - colokan		
Konektor: 1 x M12; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm		
		

Kotak splitter

ZDOAF03BMSS0000---STGH120MSS

Koneksi

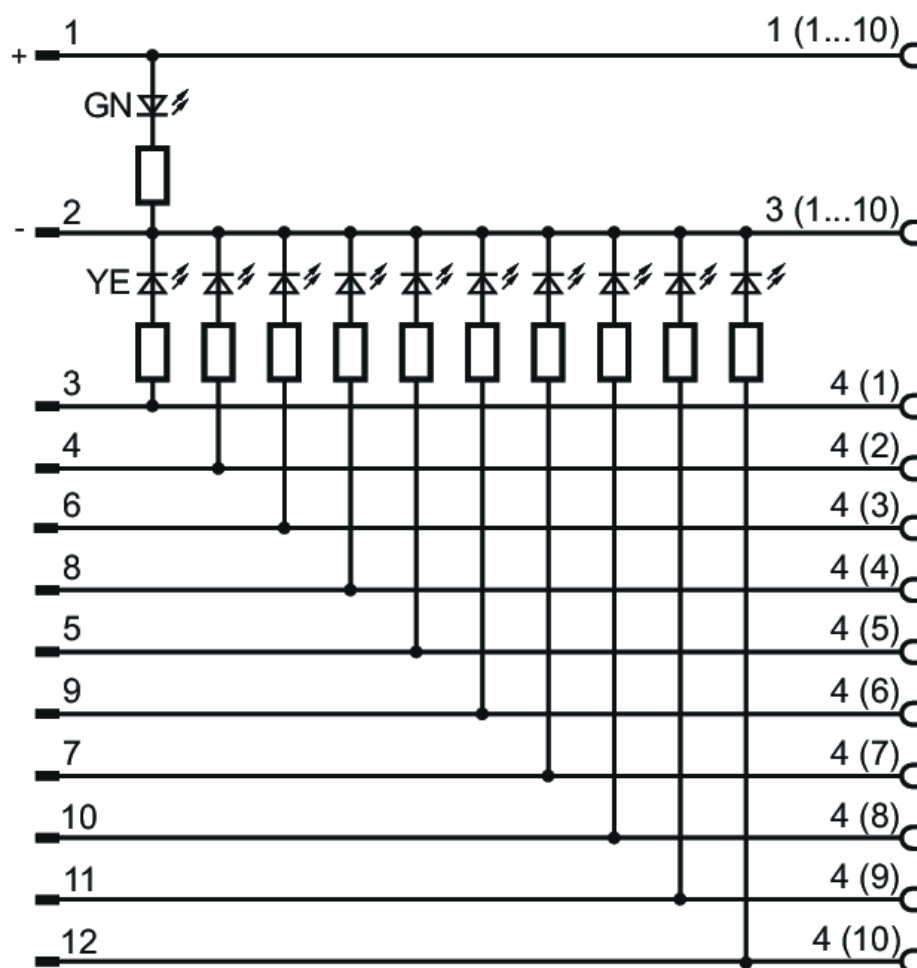

Koneksi listrik - soket

Konektor: 1 x M8; pengkodean: A; Bodi cetakan: PBT-GF 20 / kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

