


Splitter Y

ZDO2H050VAS0000-00STGH050VAS

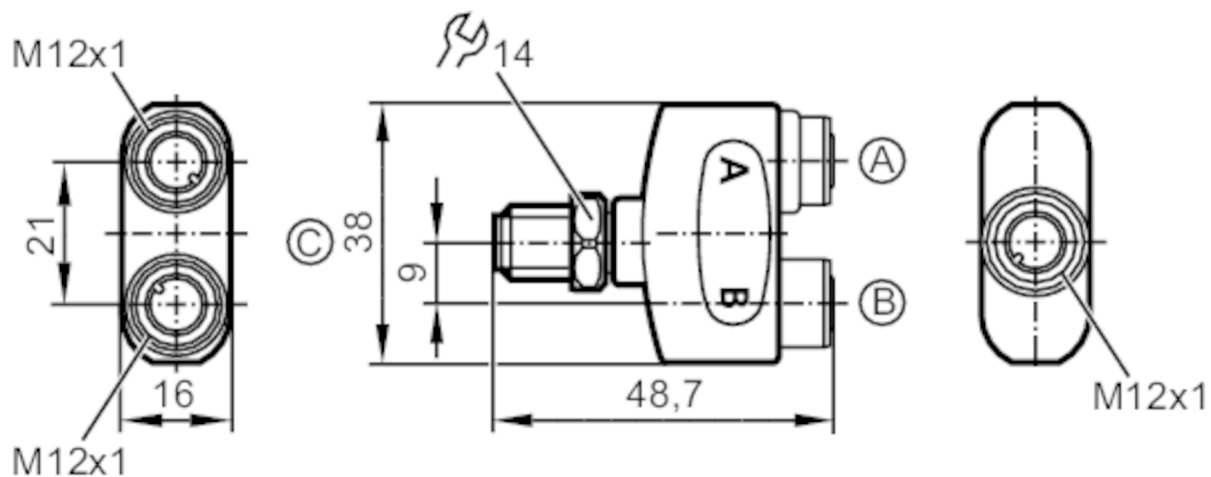

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Aplikasi	fungsi logic OR
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 60 AC/DC; (cULus: 30 AC / 42 DC)
Kelas perlindungan	II
Beban arus maks. per modul/slot [A]	4
Total beban arus maks. [A]	4
Peringkat arus keseluruhan (UL) [A]	3

Kondisi pengoperasian

Suhu sekitar [°C]	-25...100
Catatan tentang suhu sekitar	cULus: ...65 °C
Suhu penyimpanan [°C]	-25...55
Kelembapan penyimpanan [%]	10...100
Kondisi cuaca lainnya untuk penyimpanan sesuai dengan kelas yang dinyatakan	1K22/ DIN 60721-3-1
Perlindungan	IP 65; IP 67; IP 68; IP 69K

Pengujian/persetujuan

Persetujuan UL	suplai tegangan	Class 2
	Nomor file UL	E191684




Splitter Y

ZDO2H050VAS0000-00STGH050VAS


Data teknis		
Berat	[g]	33.9
Material	casing: PA Bebas halogen; Segel: EPDM	
Material bodi detakan	PA, Bebas halogen	
Material mur	baja tahan karat (1.4404 / 316L)	
Keterangan		
Jumlah paket	1 buah	

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: PA, Bebas halogen; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.2 Nm

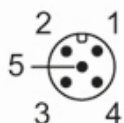

Koneksi

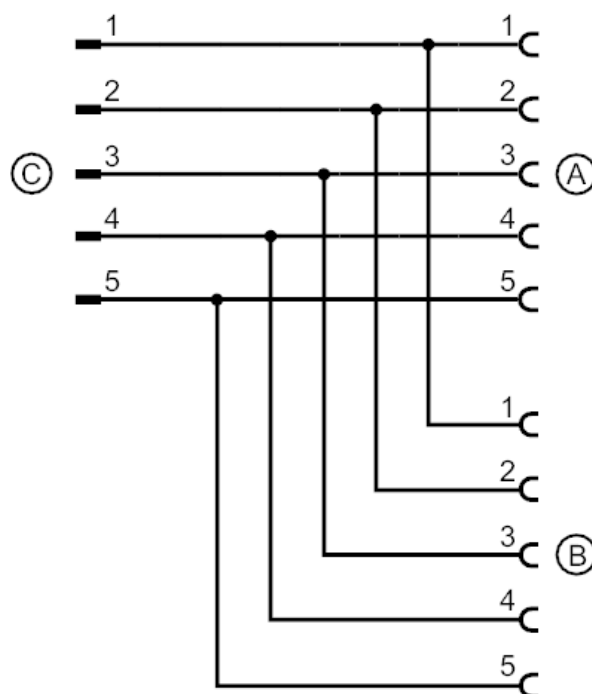

koneksi sesuai dengan IEC 61076-2-101



Splitter Y

ZDO2H050VAS0000-00STGH050VAS

Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Bodi cetakan: PA, Bebas halogen; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

