


Splitter Y

ZDO2H040VAS0000-00STGH040VAS

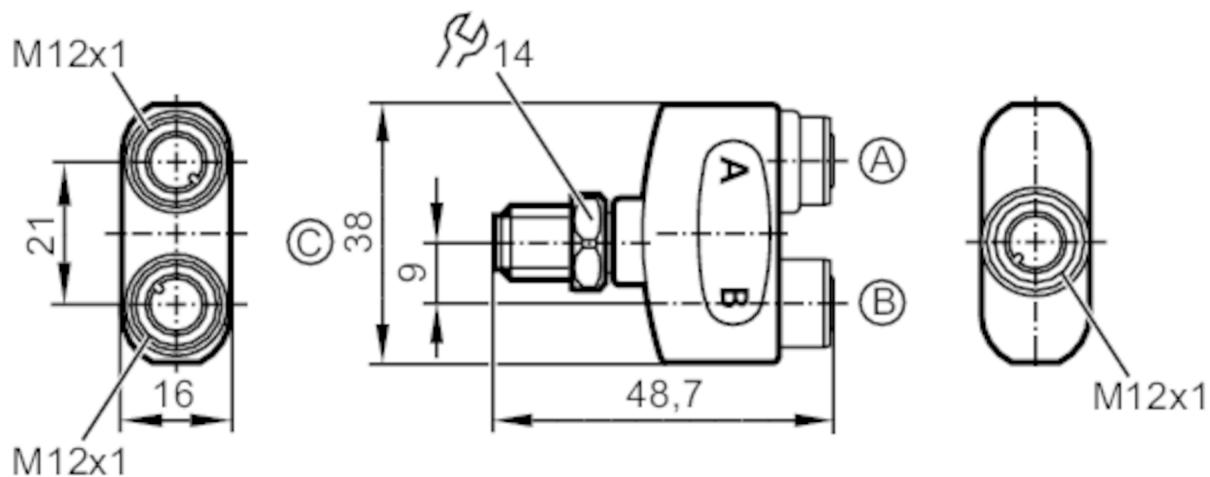

Aplikasi

Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Aplikasi	fungsi logic AND
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	< 60 AC/DC; (cULus: 30 AC / 42 DC)
Kelas perlindungan		II
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...100
Catatan tentang suhu sekitar		cULus: ...65 °C
Suhu penyimpanan	[°C]	-25...55
Kelembapan penyimpanan	[%]	10...100
Kondisi cuaca lainnya untuk penyimpanan sesuai dengan kelas yang dinyatakan		1K22/ DIN 60721-3-1
Perlindungan		IP 65; IP 67; IP 68; IP 69K

Pengujian/persetujuan

Persetujuan UL	suplai tegangan	Class 2
	Nomor file UL	E191684

Data teknis

Berat	[g]	33.8
-------	-----	------



Splitter Y

ZDO2H040VAS0000-00STGH040VAS


Material	casing: PA Bebas halogen; Segel: EPDM
Material bodi detakan	PA, Bebas halogen
Material mur	baja tahan karat (1.4404 / 316L)

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik - colokan

Konektor: 1 x M12; pengkodean: A; Bodi cetakan: PA, Bebas halogen; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.2 Nm

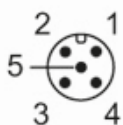

Koneksi

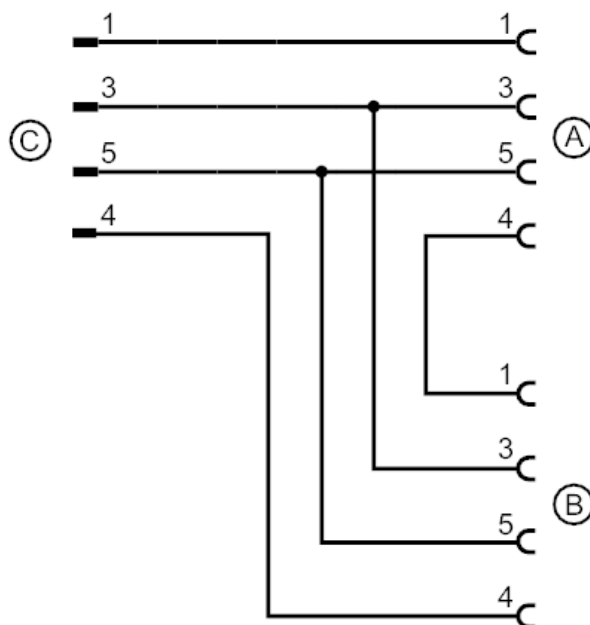

Koneksi listrik - soket

Konektor: 2 x M12; pengkodean: A; Bodi cetakan: PA, Bebas halogen; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

