



Fitur khusus	Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon	ya

Tegangan pengoperasian	[V]	10...30 DC; ("kelas suplai 2" menurut cULus)
Kelas perlindungan		II
Beban arus maks. per modul/ slot	[A]	4
Total beban arus maks.	[A]	12

Suhu sekitar	[°C]	-25...70
Suhu sekitar (bergerak)	[°C]	-5...60



Kotak splitter

ZDO8H050VAS0015E19

Perlindungan	IP 67; IP 68
--------------	--------------

Pengujian/persetujuan

Persetujuan UL	Tipe penutup	Type 1
----------------	--------------	--------

Data teknis

Berat	[g]	2875
Dimensi	[mm]	22 x 54 x 127
Material		casing: PA
Jumlah port kotak splitter		8
Tipe konektor		M12

Aksesori

Item dikirim	Tutup pelindung: 2
	label: 8

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 15 m, PVC, hitam, Ø 9.7 mm; 16 x 0.34 mm² + 3 x 1.0 mm²

Koneksi listrik - slot

Konektor: 8 x M12; pengkodean: A; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm

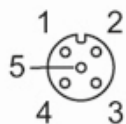



Kotak splitter

ZDO8H050VAS0015E19

Koneksi

<u>BN</u>	1 (1...8)
<u>BU</u>	3 (1...8)
<u>GN/YE</u>	5 (1...8)
<u>GY/PK</u>	2 (1)
<u>RD/BU</u>	2 (2)
<u>WH/GN</u>	2 (3)
<u>BN/GN</u>	2 (4)
<u>WH/YE</u>	2 (5)
<u>YE/BN</u>	2 (6)
<u>WH/GY</u>	2 (7)
<u>GY/BN</u>	2 (8)
<u>WH</u>	4 (1)
<u>GN</u>	4 (2)
<u>YE</u>	4 (3)
<u>GY</u>	4 (4)
<u>PK</u>	4 (5)
<u>RD</u>	4 (6)
<u>BK</u>	4 (7)
<u>VT</u>	4 (8)

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning