


EBT005



Kotak splitter

ZDO8H050VAS000---KA

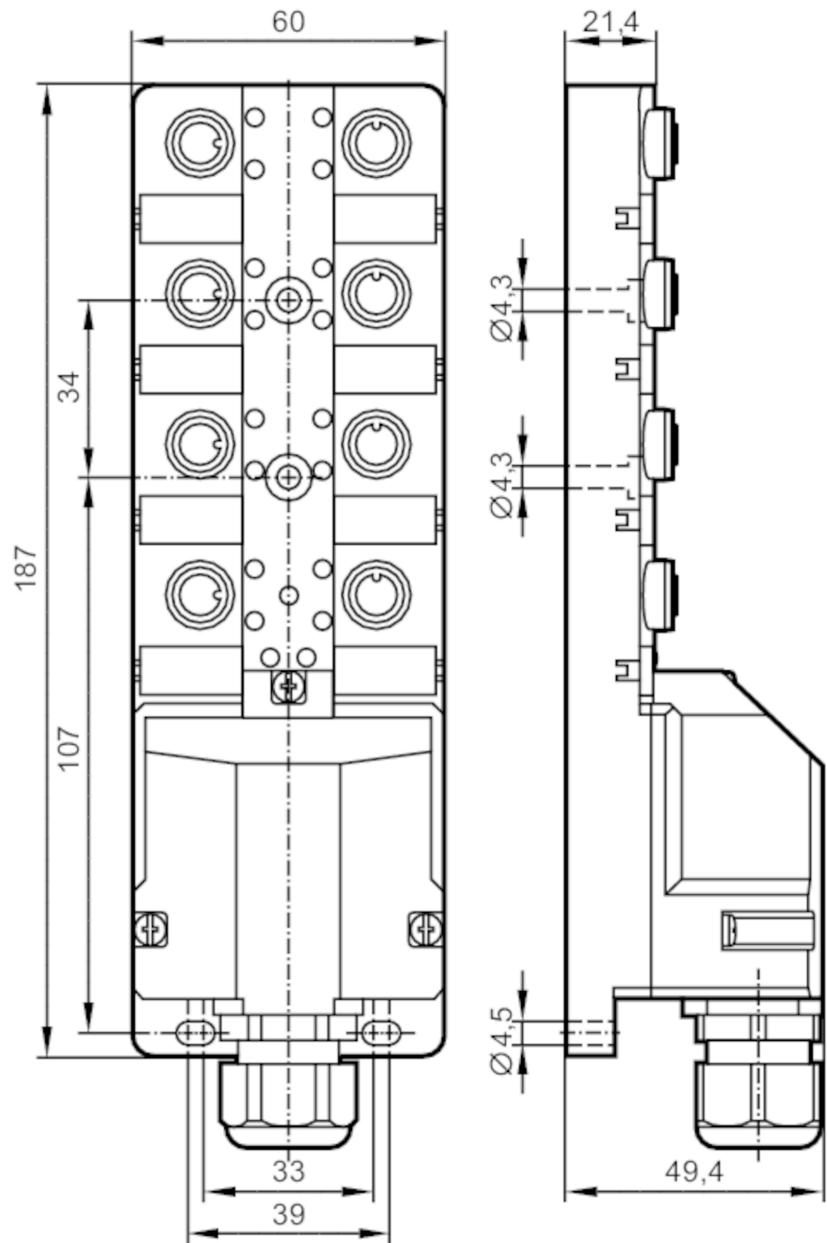


Aplikasi		
Fitur khusus		Bebas dari silikon; Kontak berlapis emas
Bebas dari silikon		ya
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Beban arus maks. per modul/slot	[A]	2
Total beban arus maks.	[A]	12
Output		
Desain kelistrikan		PNP



Kotak splitter


ZDO8H050VAS000---KA

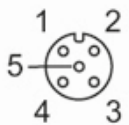Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Suhu sekitar (bergerak)	[°C]	-5...60
Perlindungan		IP 67
Data teknis		
Berat	[g]	404.5
Dimensi	[mm]	49.4 x 60 x 187
Material		kuningan berlapis nikel; casing: PBT-GF30
Jumlah port kotak splitter		8
Tipe konektor		M12
Aksesori		
Item dikirim		Tutup pelindung: 2
		label: 10
		alat perakitan untuk klem cage
Keterangan		
Jumlah paket		1 buah
Koneksi listrik - Koneksi		
terminal, sinyal: 16 x 0.34...0.75 mm ² ; Konektor kabel: M20x1.5		
terminal, suplai tegangan: 3 x 0.34...1.5 mm ²		
Konektor: 1 x M12; pengkodean: A; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm		
		

Kotak splitter

ZDO8H050VAS000---KA

Koneksi

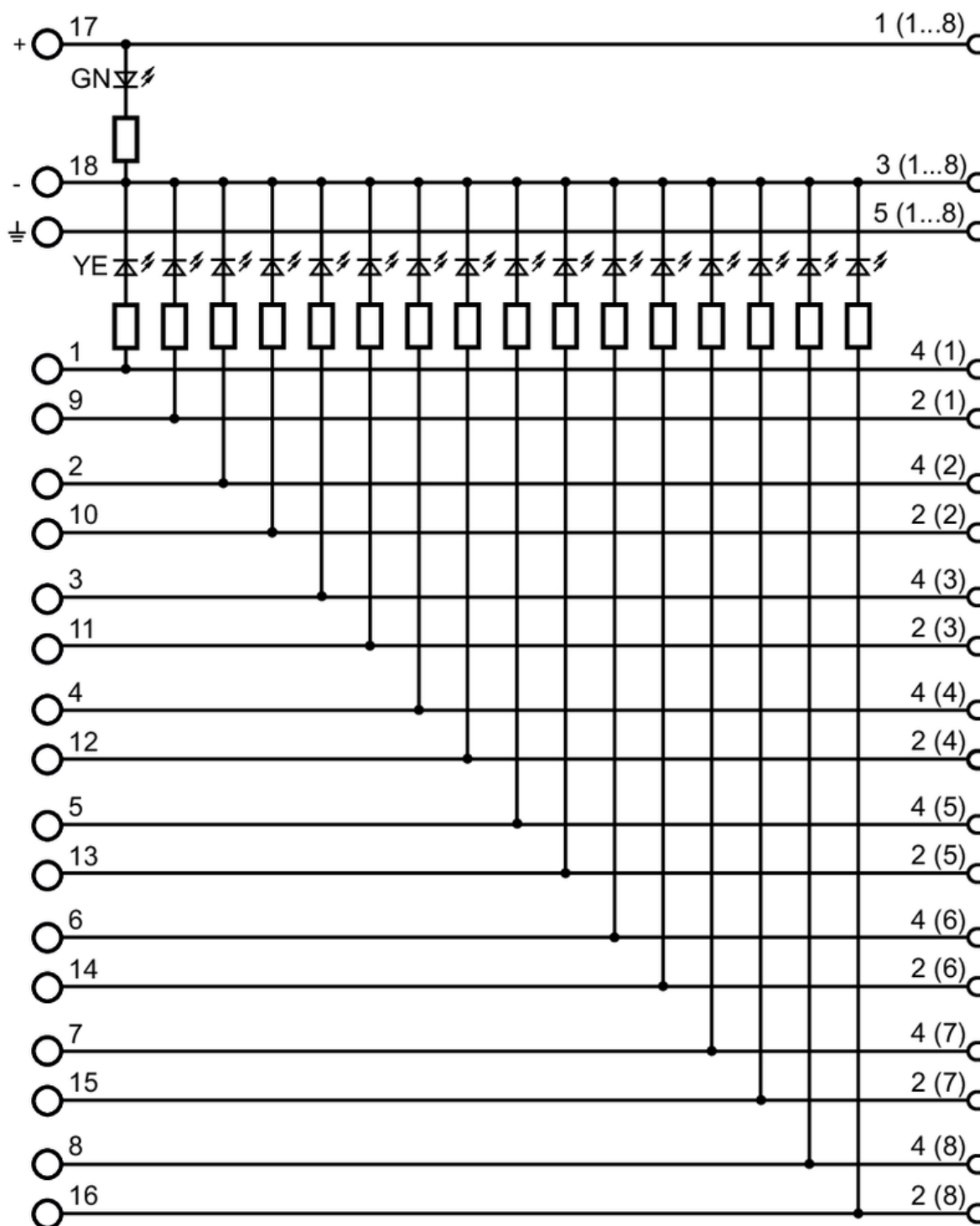

Koneksi listrik - slot

Konektor: 8 x M12; Kontak: dilapisi emas; Torsi pengencangan: 0.8...1.5 Nm