


Konverter DC-DC

R360/DC/DC-CONVERTER/10V

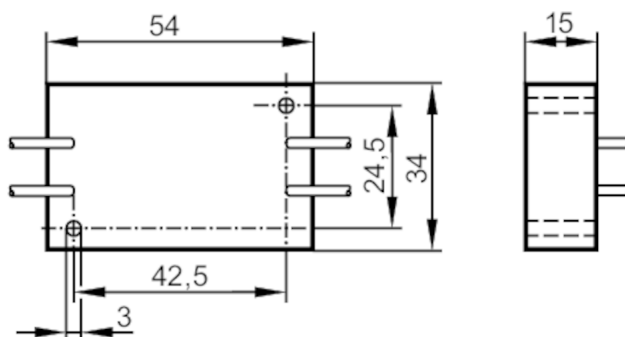

Aplikasi		
Desain		modul casing
Data kelistrikan		
Tegangan pengoperasian	[V]	18...36 DC
Output		
Tegangan output	[V]	10
Pelindung hubung singkat		ya
Pelindung beban berlebih		ya
Akurasi/deviasi		
Akurasi		± 2 %
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...71
Perlindungan		IP 67
Data teknis		
Berat	[g]	71
Dimensi	[mm]	54 x 34 x 15
Material		casing: poliamida diperkuat dengan serat kaca posisi penuh di dalam pot
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 0.28 m; Ujung core dengan selongsong ujung kawat		
input		
merah	18...36 V	
hitam	GND	
Output		
hitam	10 V DC	
biru	GND	