


EC2088



Kabel jumper dengan soket katup

R360/DANFOSS PVEH-F/M12

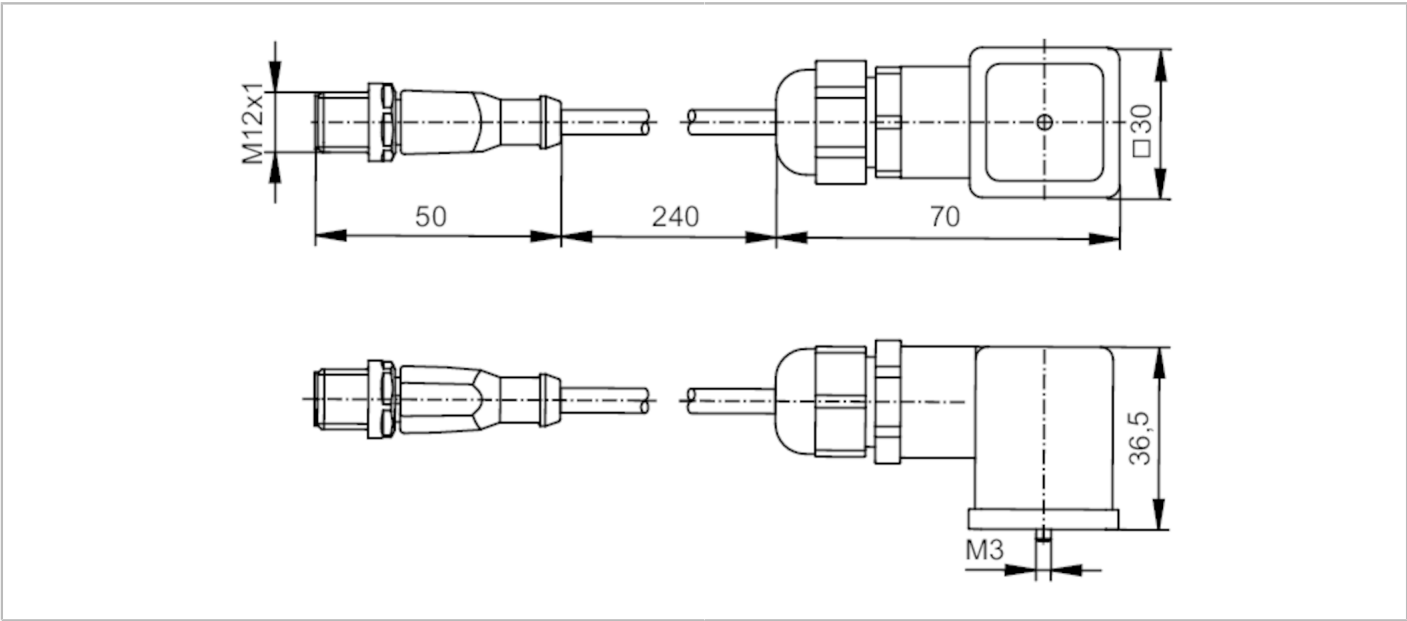

Aplikasi		
Fitur khusus		Bebas halogen
Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Kelas perlindungan		II
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Catatan tentang suhu sekitar		soket katup: -30 ... 90 °C
		Konektor M12: -25 ... 90 °C
Perlindungan		IP 65; (Konektor M12: IP65, IP67, IP68, IP69K)
Data teknis		
Berat	[g]	82
Material bodi detakan		PA-GF, Bebas halogen / TPU, Bebas halogen
Material mur		baja, galvanis / kuningan, berlapis nikel
Material penyegel		NBR / CR
Keterangan		
Jumlah paket		1 buah




Kabel jumper dengan soket katup

R360/DANFOSS PVEH-F/M12

Koneksi listrik - soket

Konektor: 1 x katup tipe A DIN, bersiku; Bodi cetakan: PA-GF, Bebas halogen, hitam; Penguncian: baja, galvanis; Segel: NBR / CR; Kontak: kuningan; Torsi pengencangan: 0.5...0.6 Nm

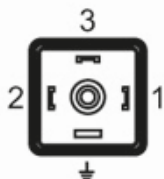


- | | |
|----|-----------|
| 1. | 24 V DC |
| 2. | PWM IN |
| 3. | Error OUT |
| | FE |

Koneksi listrik - Kabel

Kabel: 0.24 m, PUR, Bebas halogen, hitam, Ø 4.3 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi

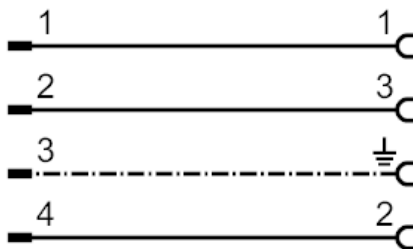

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU, Bebas halogen, oranye; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm



- | | |
|----|-----------|
| 1. | 24 V DC |
| 2. | Error OUT |
| 3. | GND |
| 4. | PWM IN |