





Kabel koneksi Y

Cable/Plug&Play/M12/0.6m

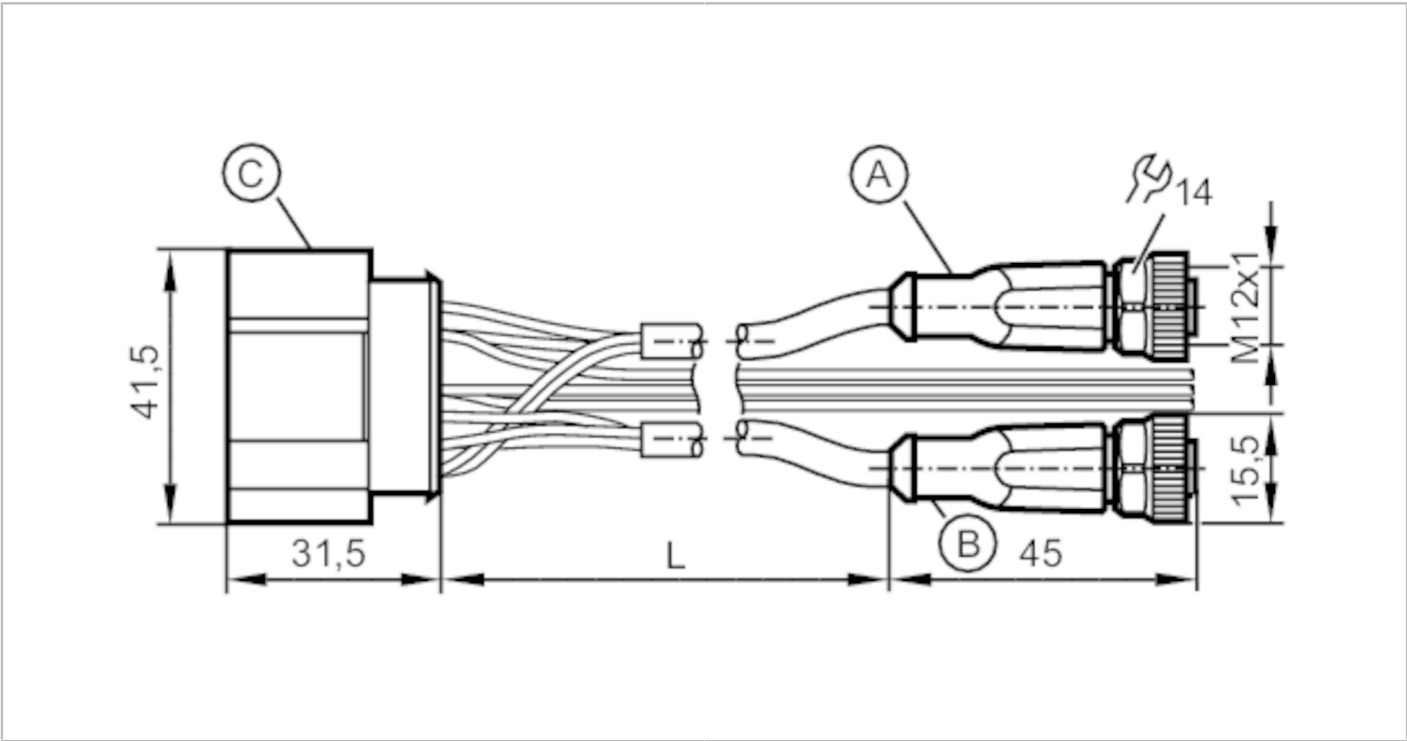

Aplikasi	
Desain	Kabel adaptor
Data kelistrikan	
Tegangan pengoperasian [V]	8...32 DC
Kondisi pengoperasian	
Suhu sekitar [°C]	-20...85
Data teknis	
Berat [g]	109
Material	casing: PBT hitam; soket: TPU oranye; Segel: Viton
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - C	

Konektor: 1 x Konektor AMP, lurus

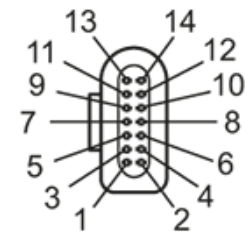

Koneksi listrik

Kabel: 0.6 m, PUR, hitam, Ø 5.1 mm; 5 x 0.5 mm²

Kabel: 0.6 m, PUR, hitam, Ø 4.9 mm; 3 x 0.5 mm²




Kabel koneksi Y

Cable/Plug&Play/M12/0.6m


Kabel: 0.6 m; 2 x 0.5 mm²

Koneksi

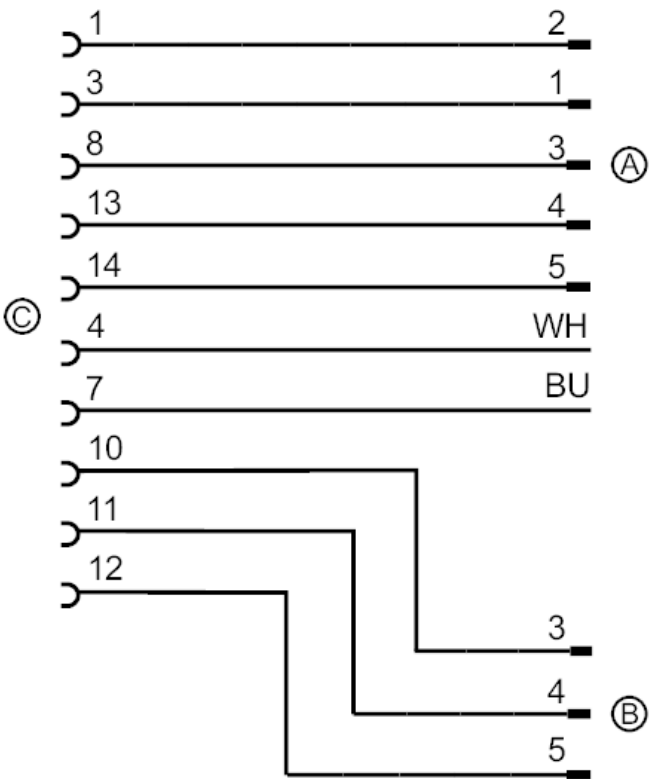

Koneksi listrik - A

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm

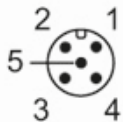

Koneksi listrik - B

Konektor: 1 x M12, lurus; pengkodean: A; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.6...1.5 Nm

