




Kabel koneksi

VDOAH030MSS03,5H03STAH030MSS

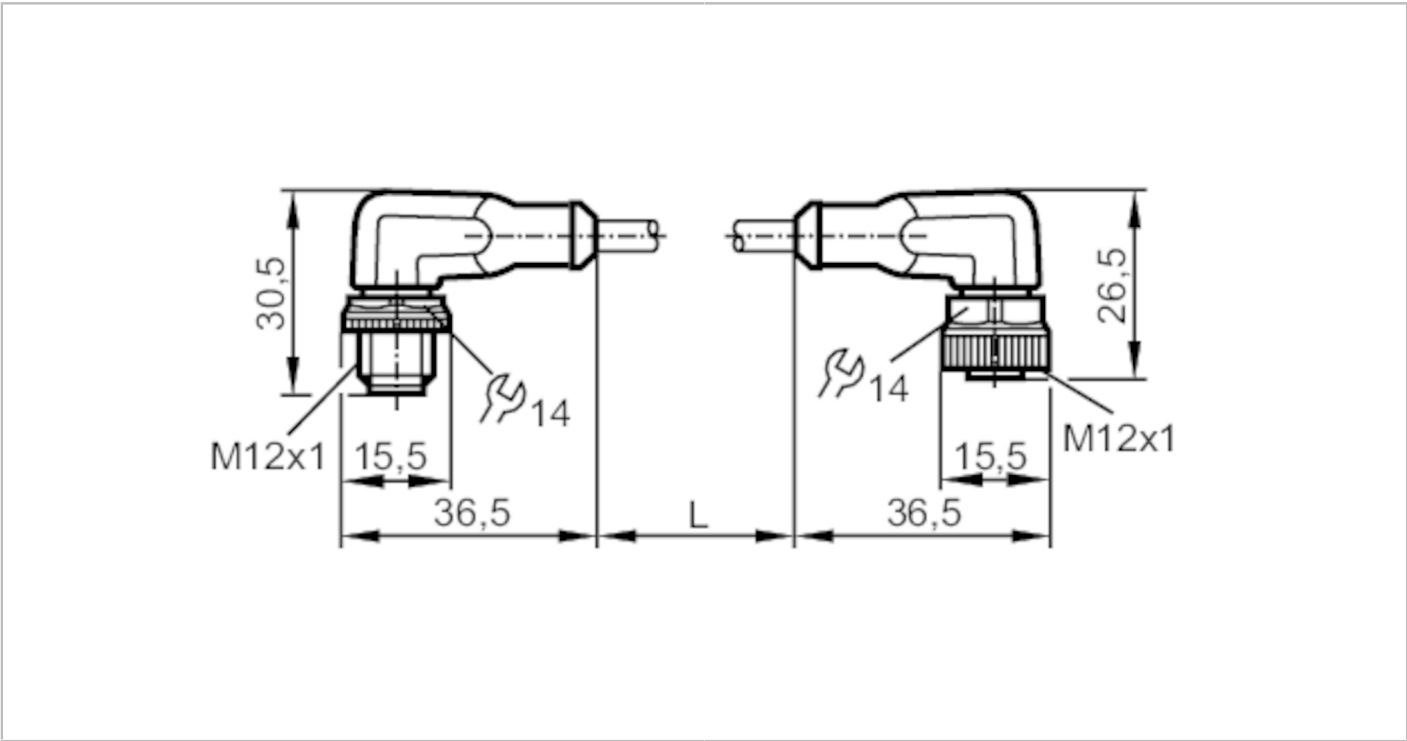

Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas; Kesesuaian rantai tarik	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
Kelas perlindungan		II
Total beban arus maks.	[A]	4
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Suhu sekitar (bergerak)	[°C]	-25...90
Perlindungan		IP 65; IP 67; IP 68; IP 69K
Data teknis		
Berat	[g]	135.6
Dimensi	[mm]	30.5 x 15.5 x 36.5
Material		casing: TPU oranye; Segel: FKM
Material mur		kuningan, berlapis nikel
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk²
	siklus pembengkokan	> 5 Mio.
	ketegangan torsional	± 180 °/m

**Kabel koneksi**

VDOAH030MSS03,5H03STAH030MSS

Keterangan

Jumlah paket


1 buah

Koneksi listrik - colokan

Konektor: 1 x M12, bersiku; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

**Koneksi listrik**

Kabel: 3.5 m, PUR, Bebas halogen, hitam, Ø 4.9 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

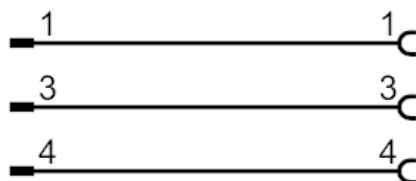Koneksi**Koneksi listrik - soket**

Konektor: 1 x M12, bersiku; pengkodean: A; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

