


# EVC961



## Kabel koneksi dengan soket

ADOAH050MSE0010C05

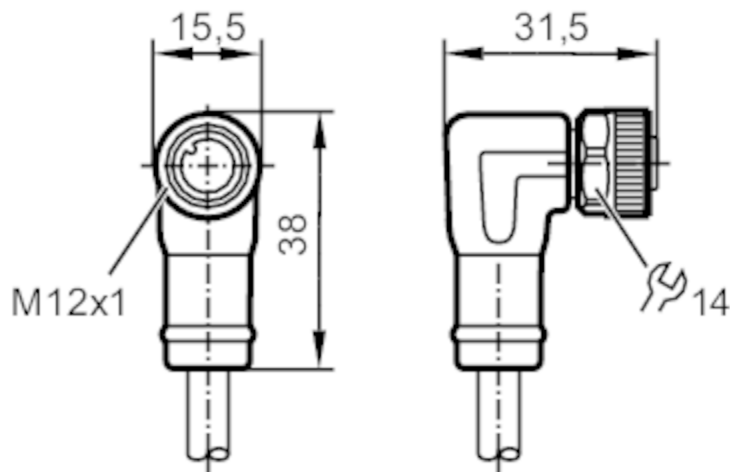

| Aplikasi                |                                                                                  |                                                                                       |
|-------------------------|----------------------------------------------------------------------------------|---------------------------------------------------------------------------------------|
| Fitur khusus            | Bebas halogen; Kontak berlapis emas; Kabel berpelindung; Kesesuaian rantai tarik |                                                                                       |
| Aplikasi                | CAN bus                                                                          |                                                                                       |
| Data kelistrikan        |                                                                                  |                                                                                       |
| Tegangan pengoperasian  | [V]                                                                              | 32 DC; (kawat 4+5: 5 V)                                                               |
| Total beban arus maks.  | [A]                                                                              | 4; (kawat 4+5: 0,05 A)                                                                |
| Kondisi pengoperasian   |                                                                                  |                                                                                       |
| Suhu sekitar            | [°C]                                                                             | -25...80                                                                              |
| Perlindungan            | IP 67; IP 68; IP 69K                                                             |                                                                                       |
| Data teknis             |                                                                                  |                                                                                       |
| Berat                   | [g]                                                                              | 983.8                                                                                 |
| Dimensi                 | [mm]                                                                             | 38 x 15.5 x 31.5                                                                      |
| Material bodi detakan   | TPU                                                                              |                                                                                       |
| Material mur            | kuningan, berlapis nikel                                                         |                                                                                       |
| Material penyegel       | FKM                                                                              |                                                                                       |
| Kesesuaian rantai tarik | ya                                                                               |                                                                                       |
| Kesesuaian rantai tarik | radius pembengkokan untuk penggunaan yang fleksibel                              | min. 10 x diameter kabel                                                              |
|                         | kecepatan pergerakan                                                             | maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk² |
|                         | siklus pembengkokan                                                              | > 5 Mio.                                                                              |
|                         | ketegangan torsional                                                             | ± 180 °/m                                                                             |
| Keterangan              |                                                                                  |                                                                                       |
| Keterangan              | Resistor pemutus CAN bus (120 Ω) diintegrasikan pada konektor M12.               |                                                                                       |



Kabel koneksi dengan soket

ADOAH050MSE0010C05


|              |        |
|--------------|--------|
| Jumlah paket | 1 buah |
|--------------|--------|

Koneksi listrik


Kabel: 10 m, PUR, Bebas halogen, ungu, Ø 8.4 mm, berpelindung; merah / hitam: 2 x 0.75 mm<sup>2</sup> (42 x Ø 0.15 mm ) + putih / biru: 2 x 0.5 mm<sup>2</sup> (19 x Ø 0.19 mm ) + penutup: 1 x 0.75 mm<sup>2</sup> (42 x Ø 0.15 mm )

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, hitam; Penguncian: kuningan, berlapis nikel; Segel: FKM; Kontak: dilapisi emas; Torsi pengencangan: 0.6...1.5 Nm

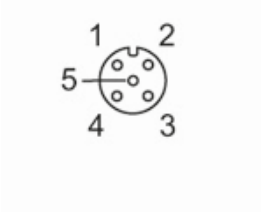

Koneksi

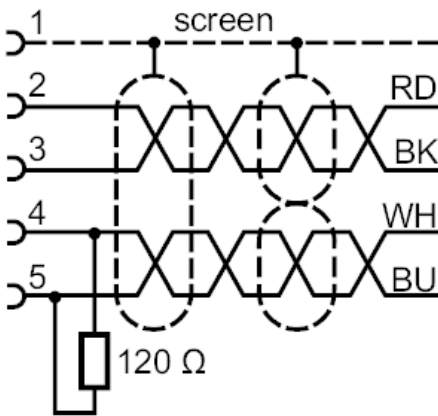

|          |              |
|----------|--------------|
|          | Warna core : |
| BK =     | hitam        |
| BU =     | biru         |
| RD =     | merah        |
| WH =     | putih        |
| screen = | penutup      |