


EVC10A



Kabel koneksi

VDOAH040VAT00,6H04STAH040VAT

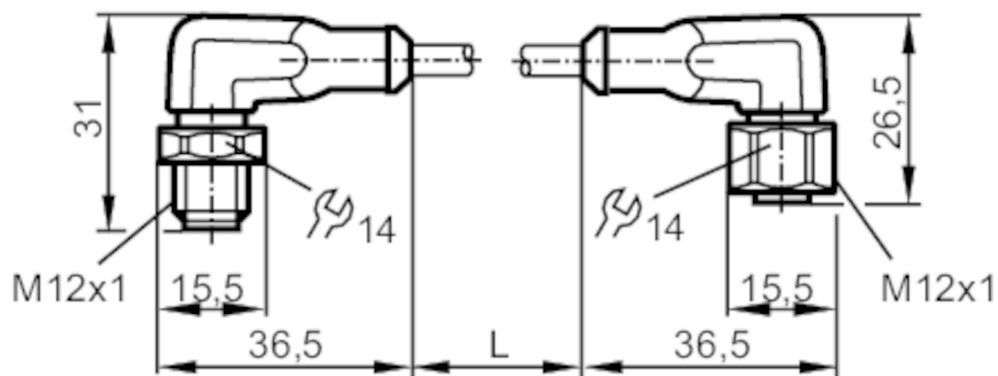

Aplikasi

Fitur khusus	Bebas halogen; Kontak berlapis emas
Kompatibel dengan cat	ya

Data kelistrikan

Tegangan pengoperasian [V]	< 60 AC/DC
Kelas perlindungan	II
Total beban arus maks. [A]	2

Kondisi pengoperasian

Suhu sekitar [°C]	-20...60
Perlindungan	IP 67; (jika digunakan di luar area berbahaya: IP 68 / IP 69K)

Pengujian/persetujuan

Persetujuan	BVS 08 ATEX E 109 U; IECEx BVS 08.0041 U
Tanda ATEX	Ex II 3G Ex ec IIC Gc; II 2D Ex tb IIIC Db IP65/IP67

Data teknis

Berat [g]	70.5
Dimensi [mm]	31 x 15.5 x 36.5
Material	casing: TPU oranye; Segel: FKM
Material mur	baja tahan karat (1.4404 / 316L)

Keterangan

Jumlah paket	1 buah
--------------	--------

EVC10A



Kabel koneksi

VDOAH040VAT00,6H04STA040VAT

Koneksi listrik - colokan

Konektor: 1 x M12, bersiku; pengkodean: A; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas; Torsi pengencangan: 1.2...1.5 Nm



Koneksi listrik

Kabel: 0.6 m, PUR, Bebas halogen, hitam, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Penguncian: baja tahan karat (1.4404 / 316L); Kontak: dilapisi emas; Torsi pengencangan: 1.2...1.5 Nm

